


Lifting point B-ABA 31,5t - M30

Artikel-Nr: 7906271

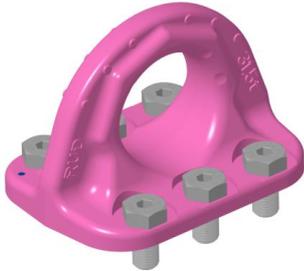


B-ABA - Sturdy and resilient

- No rattling noise or shaking even at strong vibrations or shock loads, simple hinge of lifting means possible.
- Tested and certified by DGUV Testing specifications: GS-HM-36:2021-09 Certificate No.: HM 220054
- Clear marking of the minimum WLL for all loading directions.
- Clear marking at the bolt head: RUD, thread size, batch-no., class of strength.
- Original RUD bolt with special corrosion protection Corrud-DT available as spare part.
- Available as: Standard Metric Thread (DIN EN 13)
- Patented markings for easy determination for withdraw of service.
- Pink powder coated surface.
- Significant product characteristics of the B-ABA are subject to property right claims.

Other important RUD specific information and specialities to our RUD lifting points can be found in the specific user instruction.

Lifting point B-ABA 31,5t - M30

Artikel-Nr: 7906271

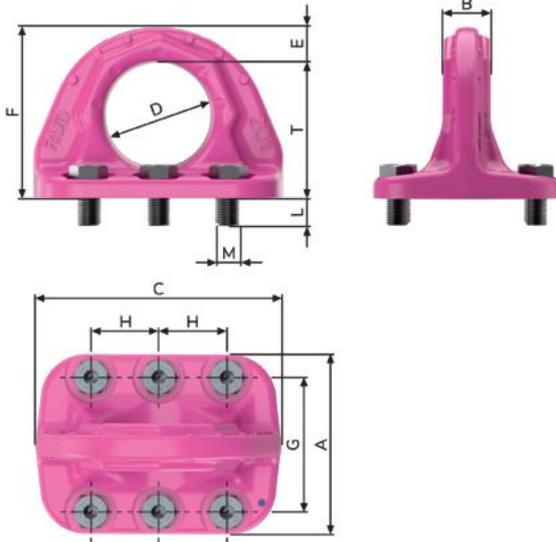

weight	29.50 kg	79.37 lbs
Nominal WLL	31500 kg	69440 lbs
T	170 mm	6-11/16"
A	230 mm	9-1/16"
B	64 mm	2-1/2"
C	320 mm	12-19/32"
D	130 mm	5-1/8"
E	50 mm	1-31/32"
F	220 mm	8-11/16"
G	175 mm	6-7/8"
H	87,5 mm	6-7/8"
L	40 mm	1-9/16"
M	M30 mm	M30