

## ICE-Eye bolt IRS-LT-M24

Artikel-Nr: 7907797




ICE-Eye bolt IRS-LT with 3x WLL acc. DIN 580 in axial direction with Axial-WLL-marking on the eye bolt.

- for low temperatures as far as  $-60^{\circ}\text{C}$ .
- Forged material 1.6541, 100% electromagnetic crack detected.
- Surface: galvanized without Chrome-VI an ICE-Pink powdercoated

Other important RUD specific information and specialities to our RUD lifting points can be found in the specific user instruction.

## ICE-Eye bolt IRS-LT-M24

Artikel-Nr: 7907797

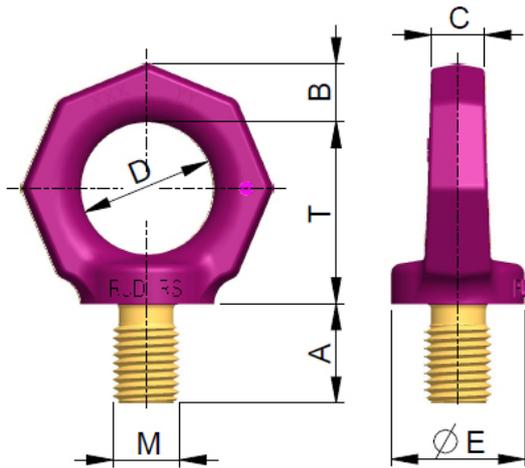

<b>weight</b>	0.89 kg	1.96 lbs
<b>Nominal WLL</b>	3750 kg	8260 lbs
<b>T</b>	70 mm	2-3/4"
<b>A</b>	36 mm	1-27/64"
<b>B</b>	21 mm	13/16"
<b>C</b>	20 mm	3/4"
<b>D</b>	50 mm	1-31/32"
<b>E</b>	50 mm	1-31/32"
<b>M</b>	M24 mm	M24