

## OPTILASH-FIX Load ring


Artikel-Nr: 7910463



- Special offset shape.
- Flat lashing angles possible.
- Can be pulled out of the guiding retainer and used for upright and oversized loads as well. (guiding retainer not included)
- Can be loaded on all sides due to optimal lateral guide and support surface.
- Corrosion protecting through phosphatisation.
- Clear indication of the lashing capacity in daN.
- Can be simply replaced with OPTILASH-CLICK in case of damage.

## OPTILASH-FIX Load ring

Artikel-Nr: 7910463

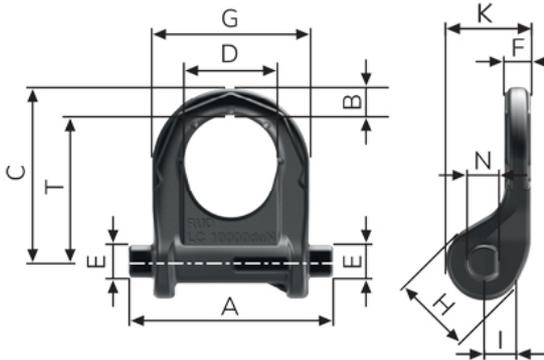

<b>weight</b>	1.93 kg	4.25 lbs
<b>T</b>	98 mm	3-27/32"
<b>A</b>	136 mm	5-11/32"
<b>B</b>	18 mm	23/32"
<b>C</b>	116 mm	4-9/16"
<b>D</b>	60 mm	2-3/8"
<b>E</b>	22 mm	7/8"
<b>F</b>	17 mm	43/64"
<b>G</b>	104 mm	4-3/32"
<b>H</b>	50 mm	1-31/32"
<b>I</b>	21,5 mm	27/32"
<b>K</b>	55 mm	2-5/32"
<b>N</b>	19 mm	3/4"
<b>Lashing capacity</b>	10000 daN	null