

OPTILASH-CLICK - with spring-loaded pin



Artikel-Nr: 7910464



- Special offset shape.
- Flat lashing angles possible.
- Can be pulled out of the guiding retainer and used for upright and oversized loads as well. (guiding retainer not included)
- Can be loaded on all sides due to optimal lateral guide and support surface.
- Can be installed in bore or guide in the vehicle frame.
- Can be fitted easily, subsequently, and from outside without tools.
- Installation possible after painting or galvanising of the vehicle frame.
- Clear indication of the lashing capacity in daN.

OPTILASH-CLICK - with spring-loaded pin

Artikel-Nr: 7910464

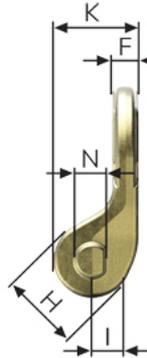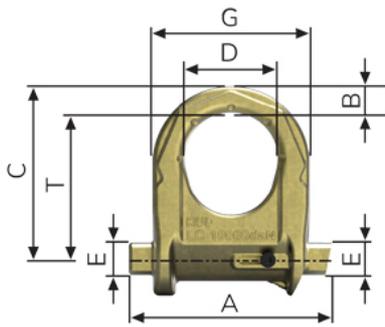

weight	1.80 kg	3.97 lbs
T	98 mm	3-27/32"
A	135 mm	5-5/16"
B	18 mm	23/32"
C	116 mm	4-9/16"
D	60 mm	2-3/8"
E	22 mm	7/8"
F	17 mm	43/64"
G	104 mm	4-3/32"
H	50 mm	1-31/32"
I	21,5 mm	27/32"
K	55 mm	2-5/32"
N	19 mm	3/4"
Lashing capacity	10000 daN	null