

STARPOINT VRS-F-16t-M56 with star key

Artikel-Nr: 7910836




- Lifting points pivots 360°. Easy adjustment in load direction.
- Not exchangeable RUD-Bolt (this reduces the usage of improper standard bolts).
- Clear marking of the minimum WLL for all loading directions. Higher WLL possible when location and installation is optimised (compare WLL chart / product information).
- Clear marking at the bolt head: RUD, thread size, batch-no.
- Variable bolt lengths available for tapped or through holes.
- Available as: - Standard Metric Thread (DIN EN 13) - Metric Fine Thread (DIN EN 13) - Coarse Pitch Thread UNC (ANSI B1.1) - Fine Thread 8UN (ANSI B1.1) - Inch Pipe Thread (DIN 228)
- Significant product characteristics of the VRS are subject to property right claims.
- Component according to the test criterias of BG/DGUV "GS-HM 36".
- Complying with the US-Standard (ASME B30.26).
- Quick and easy installation with just one bolt connection.
- Installation and disassembly without any further tools than the exchangeable Easy-Fit star profile key for singular lifts (Version VRS-F).
- For permanent installation and recurrent lifts we can offer a special socket wrench to apply the requested torque (fits to a common Inch torque wrench).

Other important RUD specific information and specialities to our RUD lifting points can be found in the specific user instruction.

STARPOINT VRS-F-16t-M56 with star key

Artikel-Nr: 7910836

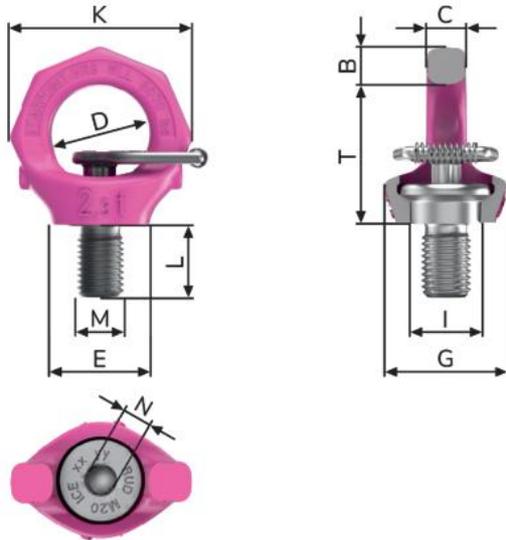

| | | |
|--------------------|----------|-----------|
| weight | 12.97 kg | 28.59 lbs |
| Nominal WLL | 16000 kg | 35270 lbs |
| T | 161 mm | 6-11/32" |
| B | 50 mm | 1-31/32" |
| C | 44 mm | 1-3/4" |
| D | 110 mm | 4-11/32" |
| E | 112 mm | 4-13/32" |
| G | 145 mm | 5-11/16" |
| I | 82 mm | 3-1/4" |
| K | 209 mm | 8-1/4" |
| L | 84 mm | 3-5/16" |
| M | M56 mm | M56 |
| N | 32 mm | 1-1/4" |