

STARPOINT VRS-F-20t-M64 with star key

Artikel-Nr: 7910837




- Lifting points pivots 360°. Easy adjustment in load direction.
- Not exchangeable RUD-Bolt (this reduces the usage of improper standard bolts).
- Clear marking of the minimum WLL for all loading directions. Higher WLL possible when location and installation is optimised (compare WLL chart / product information).
- Clear marking at the bolt head: RUD, thread size, batch-no.
- Variable bolt lengths available for tapped or through holes.
- Available as: - Standard Metric Thread (DIN EN 13) - Metric Fine Thread (DIN EN 13) - Coarse Pitch Thread UNC (ANSI B1.1) - Fine Thread 8UN (ANSI B1.1) - Inch Pipe Thread (DIN 228)
- Significant product characteristics of the VRS are subject to property right claims.
- Component according to the test criterias of BG/DGUV "GS-HM 36".
- Complying with the US-Standard (ASME B30.26).
- Quick and easy installation with just one bolt connection.
- Installation and disassembly without any further tools than the exchangeable Easy-Fit star profile key for singular lifts (Version VRS-F).
- For permanent installation and recurrent lifts we can offer a special socket wrench to apply the requested torque (fits to a common Inch torque wrench).

Other important RUD specific information and specialities to our RUD lifting points can be found in the specific user instruction.

STARPOINT VRS-F-20t-M64 with star key

Artikel-Nr: 7910837

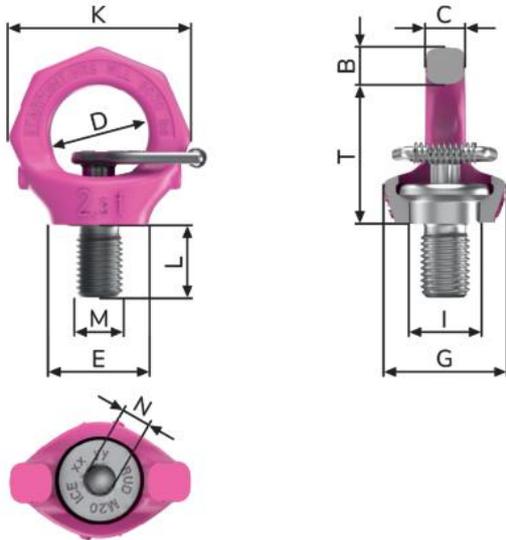

weight	17.79 kg	39.22 lbs
Nominal WLL	20000 kg	44090 lbs
T	176 mm	6-15/16"
B	55 mm	2-5/32"
C	48 mm	1-7/8"
D	120 mm	4-3/4"
E	122 mm	4-13/16"
G	157 mm	6-3/16"
I	90 mm	3-17/32"
K	228 mm	9"
L	96 mm	3-25/32"
M	M64 mm	M64
N	36 mm	1-27/64"