


Nut DIN 980-V M12-8 crack tested



Artikel-Nr: 7990534

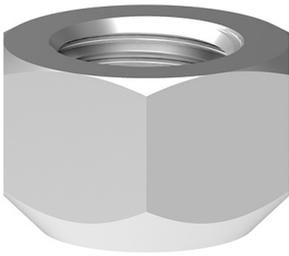

100% crack detected, prevailing torque hexagon nut type according to DIN 980 - V (all-metal design) with a zinc - plated surface. With a plain washer (extra item) suitable for the assembly of lifting points with long threaded bolts for example in through holes.

Nut DIN 980-V M12-8 crack tested

Artikel-Nr: 7990534

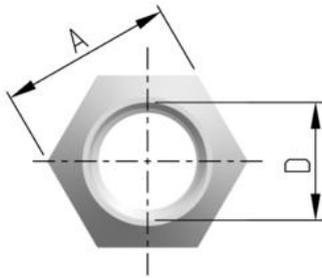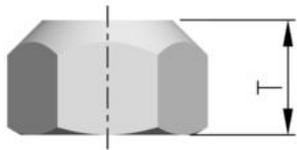

weight	0.02 kg	0.04 lbs
T	12 mm	15/32"
A	19 mm	3/4"
D	M12 mm	M12