

Lashing Point weldable LRBS 13400 daN

Artikel-Nr: 7993149




- Marked at the ring with the permitted lashing capacity "LC" in daN
- The distance lugs assist in achieving the correct air gap for the root of seam weld
- The material of the forged welding block is S355J2+N (1.0577+N)

Welding should only be carried out by qualified persons according to ISO 9606-1. Other important RUD specific information and specialities to our RUD lashing points can be found in the specific user instruction.

Lashing Point weldable LRBS 13400 daN

Artikel-Nr: 7993149

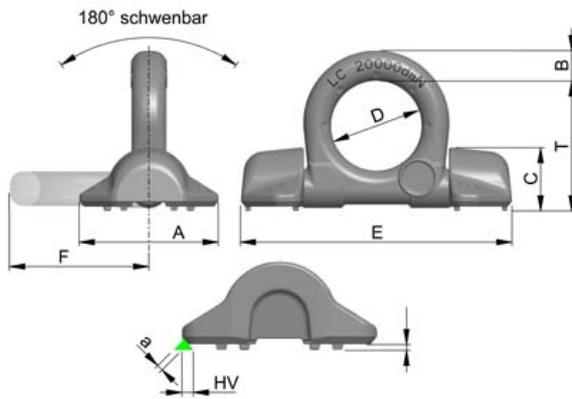

weight	1.64 kg	3.53 lbs
T	84 mm	3-5/16"
A	88 mm	3-15/32"
B	20 mm	3/4"
C	39 mm	1-9/16"
D	60 mm	2-3/8"
E	170 mm	6-11/16"
F	92 mm	3-5/8"
Lashing capacity	13400 daN	null