

Lashing Point weldable LRBS 20000 daN

Artikel-Nr: 7993150




- Marked at the ring with the permitted lashing capacity "LC" in daN
- The distance lugs assist in achieving the correct air gap for the root of seam weld
- The material of the forged welding block is S355J2+N (1.0577+N)

Welding should only be carried out by qualified persons according to ISO 9606-1. Other important RUD specific information and specialities to our RUD lashing points can be found in the specific user instruction.

Lashing Point weldable LRBS 20000 daN

Artikel-Nr: 7993150

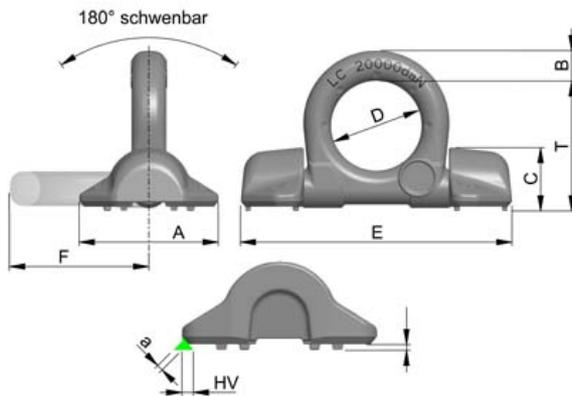

weight	2.62 kg	5.78 lbs
T	95 mm	3-3/4"
A	100 mm	3-15/16"
B	22 mm	7/8"
C	46 mm	1-13/16"
D	65 mm	2-9/16"
E	195 mm	7-11/16"
F	100 mm	3-15/16"
Lashing capacity	20000 daN	null