

Eye Plate-threaded VRBG-16t

Artikel-Nr: 7993255




Load ring threaded with full working load in all directions and split force introduction.

- Split force introduction due to multiple point fixing.
- Suspension ring pivots 180°.
- 100% WLL at 90 degrees in the load ring plane possible.
- Clear marking of the minimum WLL for all loading directions.
- Patented markings for easy determination for withdraw of service.
- Original RUD bolt available as spare part.
- Component according to the test criterias of DGUV "GS-HM-36".
- Assembly with flat / ring wrench or allen key possible.
- Hand tightening with appropriate wrench is sufficient for a singular lift.
- Please observe torque instructions when lifting point is permanently installed resp. at constant swivelling operations and tilting/ turning actions.

Other important RUD specific information and specialities to our RUD lifting points can be found in the specific user instruction.

Eye Plate-threaded VRBG-16t

Artikel-Nr: 7993255

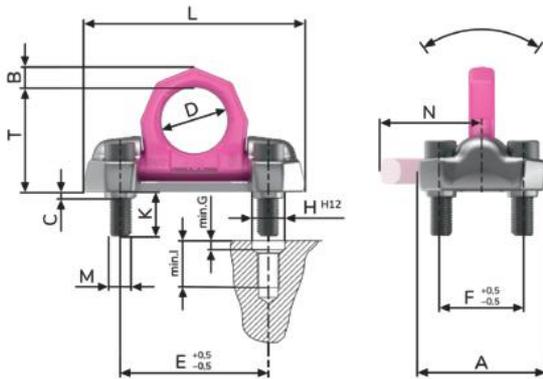

| | | |
|--------------------|----------|-----------|
| weight | 11.37 kg | 25.07 lbs |
| Nominal WLL | 16000 kg | 35270 lbs |
| T | 131 mm | 5-3/16" |
| A | 170 mm | 6-11/16" |
| B | 30 mm | 1-3/16" |
| C | 8 mm | 5/16" |
| D | 90 mm | 3-17/32" |
| E | 198 mm | 7-7/8" |
| F | 104 mm | 4-3/32" |
| G | 10 mm | 3/8" |
| H | 46 mm | 1-13/16" |
| I | 70 mm | 2-3/4" |
| K | 63 mm | 2-15/32" |
| L | 270 mm | 10-5/8" |
| M | M30 mm | M30 |
| N | 134 mm | 5-9/32" |