


## Nut DIN 980-V M14-8 crack tested



Artikel-Nr: 7993785

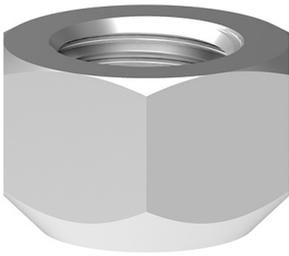

100% crack detected, prevailing torque hexagon nut type according to DIN 980 - V (all-metal design) with a zinc - plated surface. With a plain washer (extra item) suitable for the assembly of lifting points with long threaded bolts for example in through holes.

## Nut DIN 980-V M14-8 crack tested

Artikel-Nr: 7993785

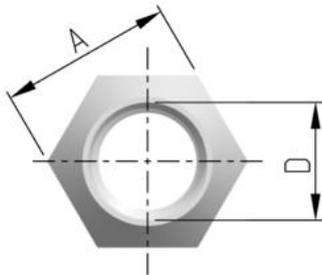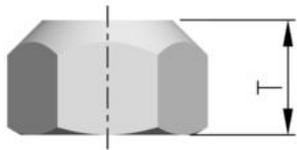

<b>weight</b>	0.03 kg	0.06 lbs
<b>T</b>	14 mm	9/16"
<b>A</b>	22 mm	7/8"
<b>D</b>	M14 mm	M14