


Nut DIN 980-V M18-8 crack tested



Artikel-Nr: 7993786

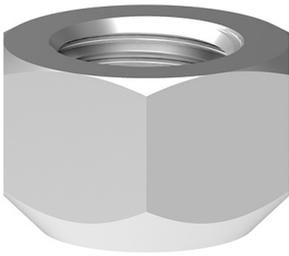

100% crack detected, prevailing torque hexagon nut type according to DIN 980 - V (all-metal design) with a zinc - plated surface. With a plain washer (extra item) suitable for the assembly of lifting points with long threaded bolts for example in through holes.

Nut DIN 980-V M18-8 crack tested

Artikel-Nr: 7993786

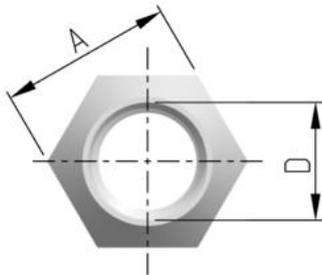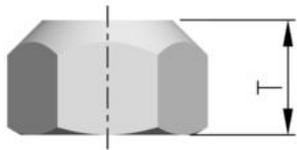

| | | |
|---------------|---------|----------|
| weight | 0.06 kg | 0.11 lbs |
| T | 18 mm | 23/32" |
| A | 27 mm | 1-1/16" |
| D | M18 mm | M18 |