


Nut DIN 980-V M33-8 crack tested



Artikel-Nr: 7993787

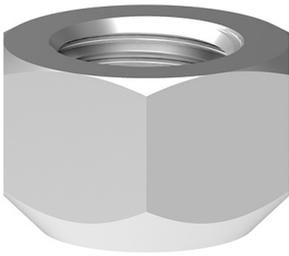

100% crack detected, prevailing torque hexagon nut type according to DIN 980 - V (all-metal design) with a zinc - plated surface. With a plain washer (extra item) suitable for the assembly of lifting points with long threaded bolts for example in through holes.

Nut DIN 980-V M33-8 crack tested

Artikel-Nr: 7993787

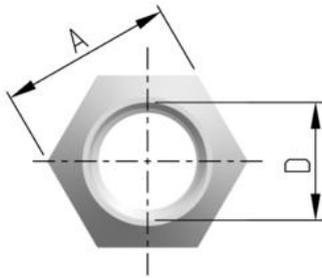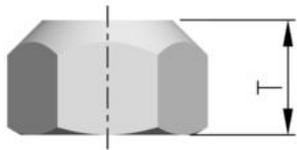

weight	0.29 kg	0.64 lbs
T	33 mm	1-5/16"
A	50 mm	1-31/32"
D	M33 mm	M33