

## Eye Plate-threaded VRBG-10t

Artikel-Nr: 7994537




Load ring threaded with full working load in all directions and split force introduction.

- Split force introduction due to multiple point fixing.
- Suspension ring pivots 180°.
- 100% WLL at 90 degrees in the load ring plane possible.
- Clear marking of the minimum WLL for all loading directions.
- Patented markings for easy determination for withdraw of service.
- Original RUD bolt available as spare part.
- Component according to the test criterias of DGUV "GS-HM-36".
- Assembly with flat / ring wrench or allen key possible.
- Hand tightening with appropriate wrench is sufficient for a singular lift.
- Please observe torque instructions when lifting point is permanently installed resp. at constant swivelling operations and tilting/ turning actions.

Other important RUD specific information and specialities to our RUD lifting points can be found in the specific user instruction.

## Eye Plate-threaded VRBG-10t

Artikel-Nr: 7994537

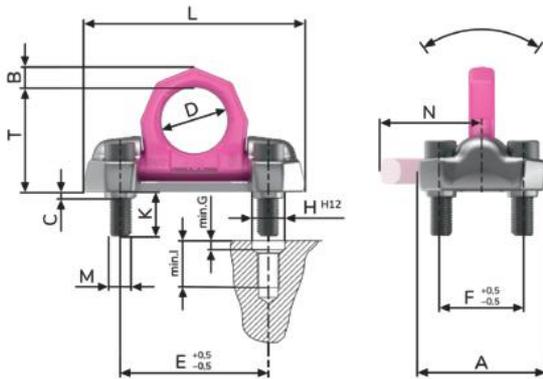

<b>weight</b>	5.43 kg	11.97 lbs
<b>Nominal WLL</b>	10000 kg	22040 lbs
<b>T</b>	103 mm	4-1/16"
<b>A</b>	125 mm	4-15/16"
<b>B</b>	22 mm	7/8"
<b>C</b>	6 mm	15/64"
<b>D</b>	65 mm	2-9/16"
<b>E</b>	143 mm	5-5/8"
<b>F</b>	78 mm	3-1/16"
<b>G</b>	8 mm	5/16"
<b>H</b>	30 mm	1-3/16"
<b>I</b>	50 mm	1-31/32"
<b>K</b>	43 mm	1-11/16"
<b>L</b>	213 mm	8-3/8"
<b>M</b>	M20 mm	M20
<b>N</b>	100 mm	3-15/16"