


Nut DIN 980-V M27-8 crack tested



Artikel-Nr: 7995736

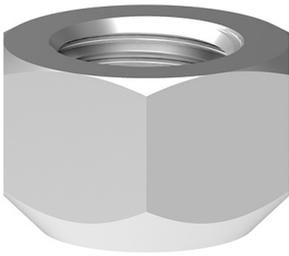

100% crack detected, prevailing torque hexagon nut type according to DIN 980 - V (all-metal design) with a zinc - plated surface. With a plain washer (extra item) suitable for the assembly of lifting points with long threaded bolts for example in through holes.

Nut DIN 980-V M27-8 crack tested

Artikel-Nr: 7995736

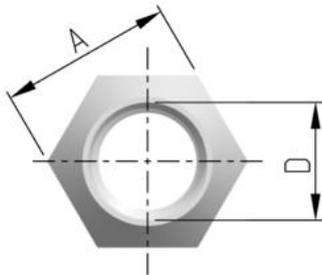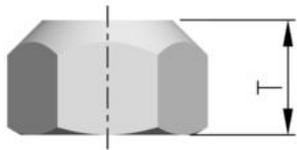

| | | |
|---------------|---------|----------|
| weight | 0.17 kg | 0.37 lbs |
| T | 27 mm | null |
| A | 41 mm | 1-5/8" |
| D | M27 mm | M27 |