

PSA-INOX-STAR-Eyebolt M12 with L=50 mm

Artikel-Nr: 7997820




- **Lifting points pivots 360°**
- **Fall arrest protection.** Statement for number of persons which can be secured.
- **Non removable special bolt**(this reduces the risk of improper standard bolts).
- Available as: – Standard Metric Thread (DIN EN 13) – Coarse Pitch Thread UNC (ANSI B1.1)
- According to EG Directive 89/686/EEG. Exceeds the requirements of DIN EN 795. Marking corresponds to DIN EN 365.
- Tested and certified by faculty PSA of DGUV.
- DGUV approval for attachment to steel and with blind rivet nuts.
- **Pentagonal shape for a clear determination to common lifting points (i.e. eye bolts).** Body and bolt made out of Duplex Steel 1.4462 (high resistancy in sea water and in environment with a high concentration of chlorine ions. Component is allowed to be used in outdoor applications.
- Quick and easy installation with just one bolt connection.
- Hand tightening with appropriate wrench is sufficient for a singular lift.

Other important RUD specific information and specialities to our RUD lifting points can be found in the specific user instruction.

PSA-INOX-STAR-Eyebolt M12 with L=50 mm

Artikel-Nr: 7997820

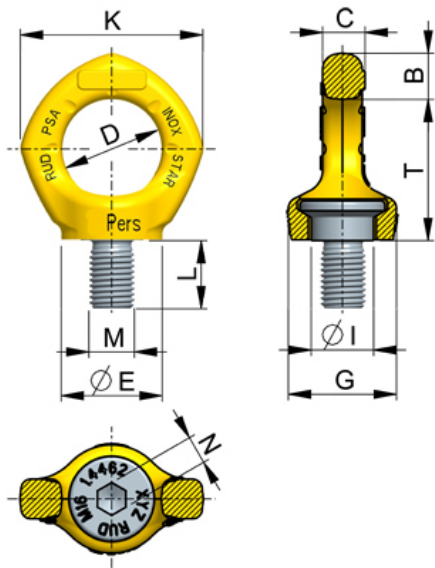

weight	0.22 kg	0.49 lbs
T	43 mm	1-11/16"
B	14 mm	9/16"
C	12 mm	15/32"
D	30 mm	1-3/16"
E	30 mm	1-3/16"
G	32 mm	1-1/4"
I	18 mm	23/32"
K	56 mm	2-3/16"
L	50 mm	1-31/32"
M	M12 mm	M12
N	8 mm	5/16"