

PSA-STARPOINT PSA-VRS 5/8"-11UNC

Artikel-Nr: 7998659




- **Lifting points pivots 360°**
- **They are corresponding to a "anchor point" according to European edict 2016/425** and the DIN 795:2012-10 resp. DIN CEN / TS 16415:2013-4 and they are marked with the number of load bearing persons (=1 or 2 persons).
- **These products are tested by a notified institution of DGUV** (Deutsche Gesetzliche Unfallversicherung) with the evidence of the in OSHA 1926.502: 2001/01 paragraph (d)(15) and DIN EN 50308:2005 chapter 4.5 for lifting points required Forces.
- **Non removable special bolt** (this reduces the risk of improper standard bolts).
- Available as: - Standard Metric Thread (DIN EN 13) - Coarse Pitch Thread UNC (ANSI B1.1)
- Quick and easy installation with just one bolt connection.
- Hand tightening with appropriate wrench is sufficient for a singular lift.

Other important RUD specific information and specialities to our RUD lifting points can be found in the specific user instruction.

PSA-STARPOINT PSA-VRS 5/8"-11UNC

Artikel-Nr: 7998659

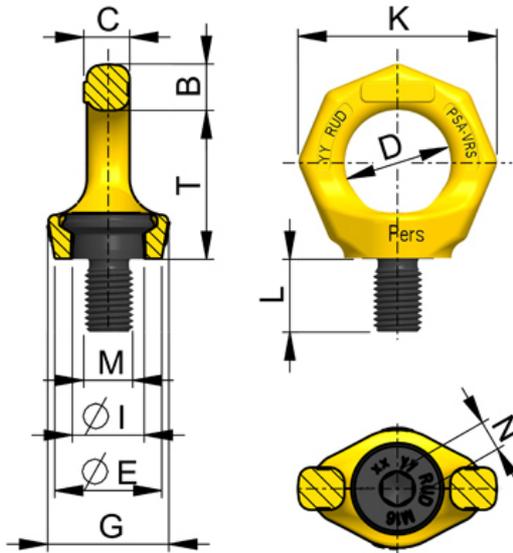

	weight	0.32 kg	0.71 lbs
T	49 mm	1-15/16"	
B	15 mm	19/32"	
C	15 mm	19/32"	
D	35 mm	1-3/8"	
E	35 mm	1-3/8"	
G	39 mm	1-9/16"	
I	23,5 mm	59/64"	
K	65 mm	2-9/16"	
L	24 mm	15/16"	
M	5/8"-11UNC mm	5/8"-11UNC	
N	3/8" mm	3/8"	