

STARPOINT VRS-1,5t-G2"

Artikel-Nr: 7999164




Vario-Starpoint VRS with adapter to pipe thread G2" DIN ISO 228-1.

- Lifting points pivots 360°. Easy adjustment in load direction.
- Not exchangeable RUD-Bolt (this reduces the usage of improper standard bolts).
- Clear marking of the minimum WLL for all loading directions. Higher WLL possible when location and installation is optimised (compare WLL chart / product information).
- Clear marking at the bolt head: RUD, thread size, batch-no.
- Variable bolt lengths available for tapped or through holes.
- Available as: - Standard Metric Thread (DIN EN 13) - Metric Fine Thread (DIN EN 13) - Coarse Pitch Thread UNC (ANSI B1.1) - Fine Thread 8UN (ANSI B1.1) - Inch Pipe Thread (DIN 228)
- Significant product characteristics of the VRS are subject to property right claims.
- Component according to the test criterias of BG/DGUV "GS-HM 36".
- Complying with the US-Standard (ASME B30.26). Quick and easy installation with just one bolt connection.
- Installation and disassembly without any further tools than the exchangeable Easy-Fit star profile key for singular lifts (Version VRS-F).
- For permanent installation and recurrend lifts we can offer a special socket wrench to apply the requested torque (fits to a common Inch torque wrench).

Other important RUD specific information and specialities to our RUD lifting points can be found in the specific user instruction.

STARPOINT VRS-1,5t-G2"

Artikel-Nr: 7999164

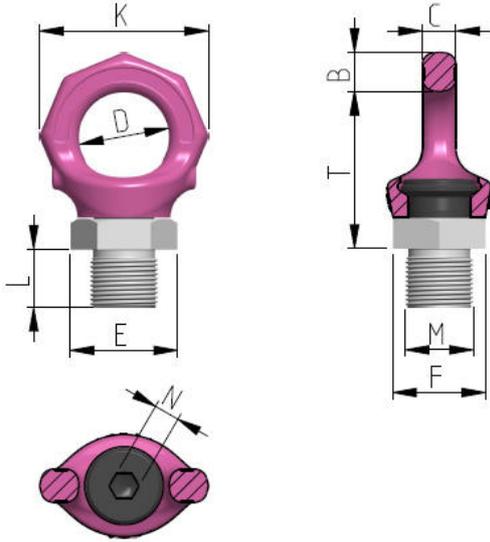

| | | |
|--------------------|---------|----------|
| weight | 1.50 kg | 3.31 lbs |
| Nominal WLL | 1500 kg | 3300 lbs |
| T | 64 mm | 2-1/2" |
| B | 15 mm | 19/32" |
| C | 13 mm | 1/2" |
| D | 35 mm | 1-3/8" |
| E | 81 mm | 3-3/16" |
| F | 70 mm | 2-3/4" |
| I | 70 mm | 2-3/4" |
| K | 65 mm | 2-9/16" |
| L | 45 mm | 1-25/32" |
| M | G 2" mm | G 2" |
| N | 10 mm | 3/8" |