

So-PowerPoint PP-VIP6-1,3t-M16X1,5 with variable length

Artikel-Nr: 8600321



Thread reach from $F = 16-70$ mm is available. (with through thread)

When ordering implicitly indicate the required length.

Connection only with RUD approved components e.g; VCÖH-6, oval link, PP 1,3t or the 6 mm VIP chain.


Hint : The VIP chain connection is fool proof. When assembling the components, pay attention to the correct WLL allocation.

- **Can be combined with most commercial lifting means without additional connecting element.**
- **Lifting points pivots 360°.**
- **Large distance between bolt-on surface and load to avoid damage.**
- **Rotatable at nominal WLL, 90° to the bolt-on direction**Lowest kinking possibility due to cardan joint.
- **Suspension ring with enlarged pivoting area.**
- Clear marking of the minimum WLL for all loading directions.
- Variable thread lengths are available for use of threaded holes and through hole fixtures.
- Non removable special bolt (this reduces the risk of non standard bolts).
- Component according to the test criterias of BG/DGUV "GS-HM 36".
- Quick and easy installation with just one bolt connection.
- Hand tightening with appropriate wrench is sufficient for a singular lift.
- Please observe torque instructions when lifting point is permanently installed resp. at constant swivelling operations and tilting/ turning actions.

Other important RUD specific information and specialities to our RUD lifting points can be found in the specific user instruction.

So-PowerPoint PP-VIP6-1,3t-M16X1,5 with variable length

Artikel-Nr: 8600321

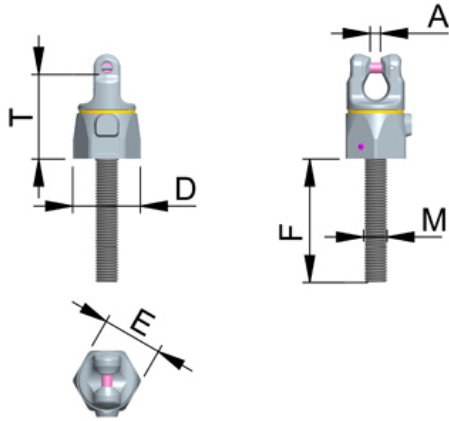

	Nominal WLL	1300 kg	2860 lbs
T	58 mm	2-9/32"	
A	6 mm	15/64"	
D	48 mm	1-7/8"	
E	41 mm	1-5/8"	
F	16-70 mm	5/8" to 2-3/4"	
M	M16X1,5 mm	M16x1,5	