

So-PowerPoint PP-VIP8-2t-M22 with F=33 mm

Artikel-Nr: 8600322



With threadlength $F = 33$ mm - When ordering implicitly indicate the required length. Connection only with RUD approved components e.g; VCÖH-8, oval link, PP 2t kg or the 8 mm VIP chain.


Hint : The VIP chain connection is fool proof. When assembling the components, pay attention to the correct WLL allocation.

- **Can be combined with most commercial lifting means without additional connecting element.**
- **Lifting points pivots 360°.**
- **Large distance between bolt-on surface and load to avoid damage.**
- **Rotatable at nominal WLL, 90° to the bolt-on direction** Lowest kinking possibility due to cardan joint.
- Clear marking of the minimum WLL for all loading directions.
- Variable thread lengths are available for use of threaded holes and through hole fixtures.
- Non removable special bolt (this reduces the risk of non standard bolts).
- Component according to the test criterias of BG/DGUV "GS-HM 36".
- Quick and easy installation with just one bolt connection.
- Hand tightening with appropriate wrench is sufficient for a singular lift.
- Please observe torque instructions when lifting point is permanently installed resp. at constant swivelling operations and tilting/ turning actions.

Other important RUD specific information and specialities to our RUD lifting points can be found in the specific user instruction.

So-PowerPoint PP-VIP8-2t-M22 with F=33 mm

Artikel-Nr: 8600322

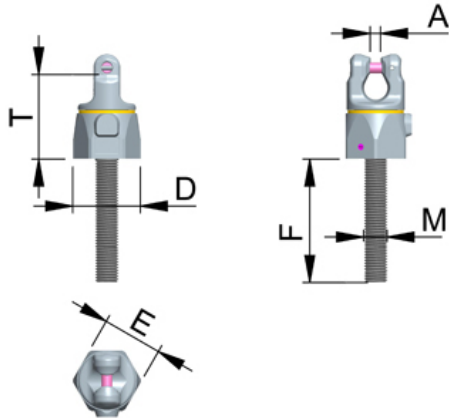

weight	1.20 kg	2.65 lbs
Nominal WLL	2000 kg	4400 lbs
T	73 mm	2-7/8"
A	8 mm	5/16"
D	62 mm	2-7/16"
E	55 mm	2-5/32"
F	33 mm	1-5/16"
M	M22 mm	M22