

So-PowerPoint PP-VIP13-5t-M30X2 with variable length

Artikel-Nr: 8600324



Thread reach from $F = 30-125$ mm is available. (with through thread)

When ordering implicitly indicate the required length.

Connection only with RUD approved components e.g; VCÖH-13, oval link, PP 5t or the 13 mm VIP chain.


Hint : The VIP chain connection is fool proof. When assembling the components, pay attention to the correct WLL allocation.

- **Can be combined with most commercial lifting means without additional connecting element.**
- **Lifting points pivots 360°.**
- **Large distance between bolt-on surface and load to avoid damage.**
- **Rotatable at nominal WLL, 90° to the bolt-on direction**Lowest kinking possibility due to cardan joint.
- **Suspension ring with enlarged pivoting area.**
- Clear marking of the minimum WLL for all loading directions.
- Variable thread lengths are available for use of threaded holes and through hole fixtures.
- Non removable special bolt (this reduces the risk of non standard bolts).
- Component according to the test criterias of BG/DGUV "GS-HM 36".
- Quick and easy installation with just one bolt connection.
- Hand tightening with appropriate wrench is sufficient for a singular lift.
- Please observe torque instructions when lifting point is permanently installed resp. at constant swivelling operations and tilting/ turning actions.

Other important RUD specific information and specialities to our RUD lifting points can be found in the specific user instruction.

So-PowerPoint PP-VIP13-5t-M30X2 with variable length

Artikel-Nr: 8600324

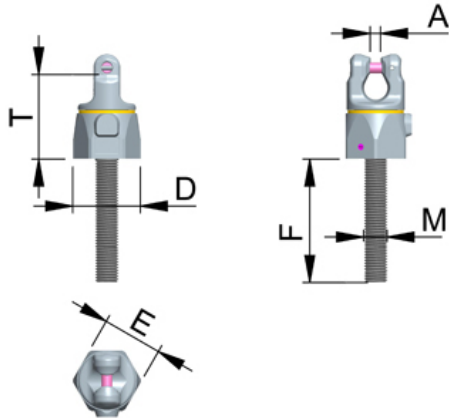

weight	0.00 kg	null
Nominal WLL	5000 kg	11000 lbs
T	108 mm	4-1/4"
A	13 mm	1/2"
D	99 mm	3-7/8"
E	85 mm	3-11/32"
F	30-125 mm	1-3/16" to 4-15/16"
M	M30X2 mm	M30x2