

PowerPoint PP-VIP4-0,63t-1/2"-12BSW

Artikel-Nr: 8600571



Connection only with RUD approved components e.g; VCÖH-4, oval link, PP 0,63t or the 4 mm VIP chain.


Hint : The VIP chain connection is fool proof. When assembling the components, pay attention to the correct WLL allocation.

- **Can be combined with most commercial lifting means without additional connecting element.**
- **Lifting points pivots 360°.**
- **Large distance between bolt-on surface and load to avoid damage.**
- **Rotatable at nominal WLL, 90° to the bolt-on direction**Lowest kinking possibility due to cardan joint.
- **Suspension ring with enlarged pivoting area.**
- Clear marking of the minimum WLL for all loading directions.
- Variable thread lengths are available for use of threaded holes and through hole fixtures.
- Non removable special bolt (this reduces the risk of non standard bolts).
- Component according to the test criterias of BG/DGUV "GS-HM 36".
- Quick and easy installation with just one bolt connection.
- Hand tightening with appropriate wrench is sufficient for a singular lift.
- Please observe torque instructions when lifting point is permanently installed resp. at constant swivelling operations and tilting/ turning actions.

Other important RUD specific information and specialities to our RUD lifting points can be found in the specific user instruction.

PowerPoint PP-VIP4-0,63t-1/2"-12BSW

Artikel-Nr: 8600571

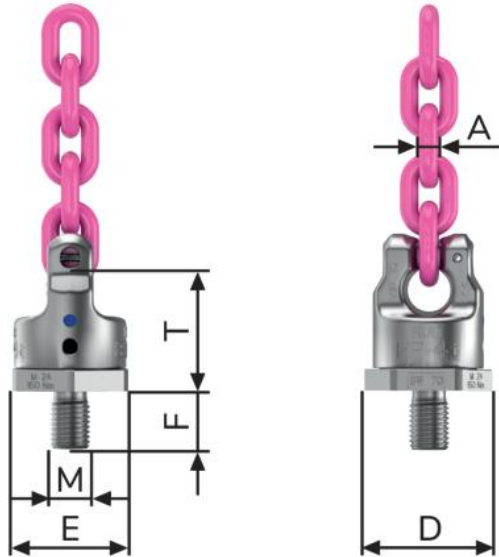

| | | |
|--------------------|---------------|------------|
| weight | 0.24 kg | 0.53 lbs |
| Nominal WLL | 630 kg | 1390 lbs |
| T | 41 mm | 1-5/8" |
| A | 4 mm | 5/32" |
| D | 40 mm | 1-9/16" |
| E | 36 mm | 1-27/64" |
| F | 18 mm | 23/32" |
| M | 1/2"-12BSW mm | 1/2"-12BSW |