

Lashing point L-VLBG-PLUS 16.000 daN M36 with variable length H=36-223 mm

Artikel-Nr: 8600778



Thread lengths of H=36-223 mm are available. When ordering implicitly indicate the required length.


The VLBG-PLUS as a boltable heavy duty lashing point for load beds and cargo.

- Clear marking of the lashing capacity for all loading directions. LC marking with daN.
- Lashing point pivots 360°. Suspension ring pivots 180°.
- Full load in all directions
- Original-RUD bolt with special corrosion protection Corrud-DT is included in delivery as well as available as a spare part. Clear marking at the bolt head: RUD, thread size, batch-no., class of strength.
- Captive but exchangeable special bolt (this reduces the usage of improper standard bolts).
- Clamping spring works as a noise reduction and holds the suspension ring in the requested position; therefore simple hinge of lashing mean possible.
- Variable bolt lengths available for tapped or through holes.
- Quick and easy installation with just one bolt connection.
- Assembly with flat / ring wrench or allen key possible.

Other important RUD specific information and specialities to our RUD lashing points can be found in the specific user instruction.

Lashing point L-VLBG-PLUS 16.000 daN M36 with variable length H=36-223 mm

Artikel-Nr: 8600778

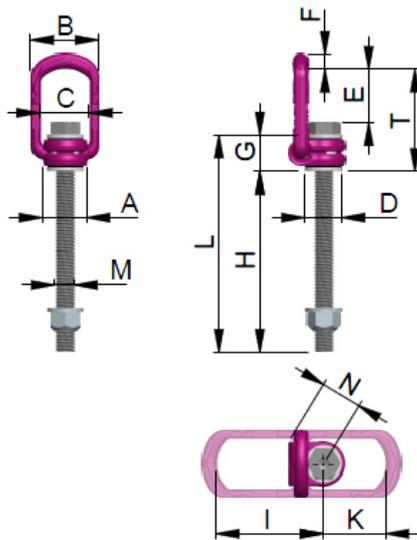

T	197 mm	7-3/4"
A	77 mm	3"-1/32"
B	122 mm	4-13/16"
C	82 mm	3-1/4"
D	70 mm	2-3/4"
E	97 mm	3-13/16"
F	26,5 mm	1-3/64"
G	77 mm	3"-1/32"
H	36-223 mm	36-223
I	205 mm	8-1/16"
K	110 mm	4-11/32"
L	113-300 mm	113-300
M	M36 mm	M36
N	87 mm	3-7/16"
Lashing capacity	16000 daN	null