


STI HORN/STROBE DAMAGE STOPPERS®

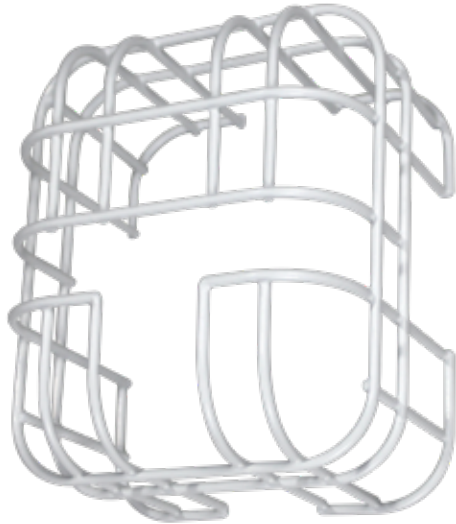

STI-9767



STI-9760

PRODUCT OVERVIEW

Wire guards are an excellent way to protect horn/strobe units against both vandalism and accidental damage. Constructed of tough 9-gauge steel wire coated with corrosion resistant red or white polyester, these guards can take hard knocks in stride. The L Series wire guards provide maximum protection for ceiling and wall mounted horn/strobes.

BACKED BY A THREE YEAR GUARANTEE

As all STI protective covers, these guards are backed by a three year guarantee against breakage in normal use. Installation and servicing are easy with all screws and anchors provided. These Stoppers are highly recommended for areas where abuse is severe, or it is imperative that horn/strobe units continue to operate.

KEY FEATURES

General Information

- Offers protection against vandalism and accidental damage.
- Simple removal for maintenance.
- For indoor use.
- Three year guarantee against breakage in normal use.
- For use with L Series horns/strobes.

Construction

- Constructed of tough 9-gauge steel wire.
- Coated with corrosion resistant polyester.
- UL Listed to U.S. and Canadian safety standards (see details on side 2).

Installation

- Installation is fast and simple with screws and anchors provided.

Options

- STI-9760, STI-9761, STI-9762, STI-9763, STI-9764, STI-9765 available with red or white coating.
- STI-9766 and STI-9767 available with white coating.



STI Horn/Strobe Damage Stoppers®

Dimensions and Technical Information

MODELS AVAILABLE

STI-9760	Horn/Strobe Damage Stopper, L Series Ceiling, White
STI-9761	Horn/Strobe Damage Stopper, L Series Ceiling, White
STI-9762	Horn/Strobe Damage Stopper, L Series Ceiling, White
STI-9762-R	Horn/Strobe Damage Stopper, L Series Wall, Red
STI-9763	Horn/Strobe Damage Stopper, L Series Wall, White
STI-9763-R	Horn/Strobe Damage Stopper, L Series Wall, Red
STI-9764	Horn/Strobe Damage Stopper, L Series Wall, White
STI-9764-R	Horn/Strobe Damage Stopper, L Series Wall, Red
STI-9765	Horn/Strobe Damage Stopper, L Series Wall, White
STI-9765-R	Horn/Strobe Damage Stopper, L Series Wall, Red
STI-9766	Horn/Strobe Damage Stopper, L Series Wall, White
STI-9767	Horn/Strobe Damage Stopper, L Series Wall, White

Model	Height	Width	Depth
STI-9760	8.5 in. (217mm)	8.5 in. (217mm)	3.2 in. (81mm)
STI-9761	8.5 in. (217mm)	8.5 in. (217mm)	5.7 in. (144mm)
STI-9762	6.2 in. (156mm)	4.76 in. (121mm)	2.5 in. (65mm)
STI-9763	6.2 in. (156mm)	4.76 in. (121mm)	4.0 in. (112mm)
STI-9764	6.6 in. (167mm)	6.0 in. (152mm)	2.5 in. (65mm)
STI-9765	6.6 in. (167mm)	6.0 in. (152mm)	4.4 in. (112mm)
STI-9766	8.2 in. (209mm)	6.75 in. (172mm)	2.9 in. (74mm)
STI-9767	8.2 in. (209mm)	6.75 in. (172mm)	5.0 in. (131mm)

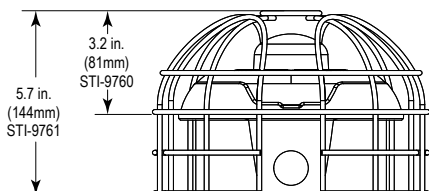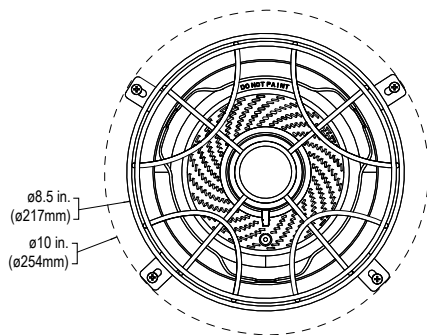

APPROVALS & WARRANTY

TESTING

UL/cUL Listed.
For use with devices Listed to UL1638, UL464, UL1480
CAN/ULC-S525CAN/ULC-S526, CAN/ULC-S541

WARRANTY

Three year guarantee against breakage in normal use.

LIGHT AND SOUND DE-RATING FACTOR

STI-9760, STI-9761

CHSCRL, CHSCWL, PC2RL-LF, PC2WL-LF, HCRL-LF, HCWL-LF, SPCWL, SPCRL, SPSCWL, SPSCRL, PC2RL, PC2WL, PC4RL, PC4WL, SCRL, SCWL light loss 41%, sound loss <1%

STI-9762, STI-9763



HGRL, HGWL, P2GRL, P2GWL, SGRL, SGWL, HGRL-LF, HGWL-LF light loss 17% sound loss <1%

STI-9764, STI-9765

HRL, HWL, CHRL, CHWL, CHSRL, CHSWL, P2RL, P2WL, P4RL, P4WL, SRL, SWL, P2RL-LF, P2WL-LF, HRL-LF, HWL-LF light loss 69%, sound loss <1%

STI-9766, STI-9767

SPRL, SPWL, SPSRL, SPSWL light loss 21%, sound loss <1%

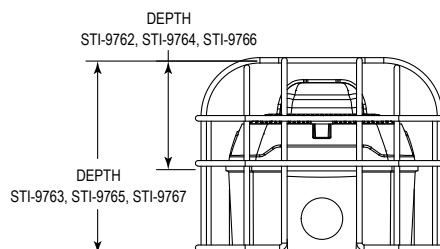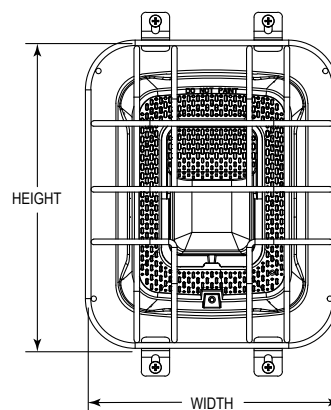

**Safety Technology
International**