

# NEMA 3R, 4, 12, and 13 Single-Door Wall-Mount



## Applications

Designed for use as electrical junction boxes, terminal wiring boxes, instrument housings, and electrical control enclosures. Provides protection from dust, dirt, oil and water.

## Construction

- 16-gauge carbon steel
- Seams continuously welded and ground smooth— no holes or knockouts
- Bolt-on continuous hinge with stainless steel pin
- Stainless steel external screw clamps are quick and easy to operate.
- Poured-in-place oil- and water-resistant gasket
- Standoffs are provided for mounting optional subpanels.
- Welded mounting provision top and bottom of back
- Ground studs on door and body

## Finish


- ANSI 61 gray powder coated inside and out
- Optional subpanels are powder coated white.

## Listings

- NEMA Type 3R, 4, 12, and 13
- cULus Listed Type 3R, 4 and 12 [File E69392]
- IEC 60529 IP66



## Dimensions

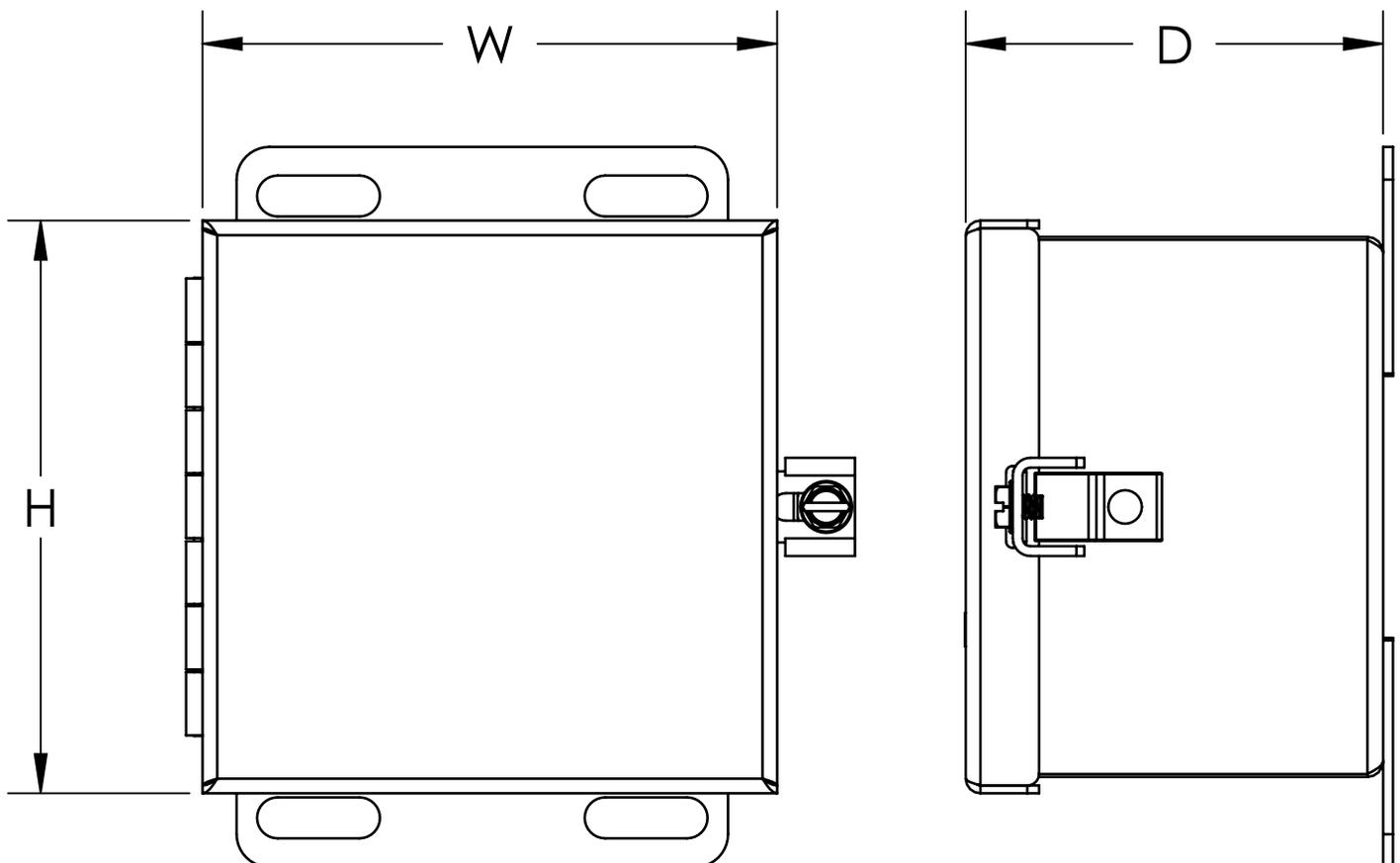

# NEMA 3R, 4, 12, and 13 Single-Door Wall-Mount



## Shipping Schedule

Same day	1 - 15 days
----------	-------------

Color indicates shipping lead time in business days.

## NEMA 3R, 4, 12, and 13 Single-Door Wall-Mount

Part Number	Price	Size HxWxD	Drawing Link	Optional Subpanel	Price
<a href="#">SCE-404CHNF</a>	\$48.50	4.38 x 4.39 x 3.20 [111 x 112 x 81]	<a href="#">PDF</a>	—	—
<a href="#">SCE-4044CHNF</a>	\$50.00	4.38 x 4.39 x 4.20 [111 x 112 x 107]	<a href="#">PDF</a>	—	—
<a href="#">SCE-604CHNF</a>	\$54.00	6.38 x 4.39 x 3.20 [162 x 112 x 81]	<a href="#">PDF</a>	<a href="#">SCE-6P4</a>	\$4.25
<a href="#">SCE-6044CHNF</a>	\$59.00	6.38 x 4.39 x 4.20 [162 x 112 x 107]	<a href="#">PDF</a>	<a href="#">SCE-6P4</a>	\$4.25
<a href="#">SCE-606CHNF</a>	\$64.00	6.38 x 6.39 x 4.20 [162 x 162 x 107]	<a href="#">PDF</a>	<a href="#">SCE-6P6</a>	\$5.00
<a href="#">SCE-806CHNF</a>	\$69.00	8.38 x 6.39 x 3.70 [213 x 162 x 94]	<a href="#">PDF</a>	<a href="#">SCE-8P6</a>	\$5.75
<a href="#">SCE-8066CHNF</a>	\$81.00	8.38 x 6.39 x 6.20 [213 x 162 x 157]	<a href="#">PDF</a>	<a href="#">SCE-8P6</a>	\$5.75
<a href="#">SCE-808CHNF</a>	\$77.00	8.38 x 8.39 x 4.20 [213 x 213 x 107]	<a href="#">PDF</a>	<a href="#">SCE-8P8</a>	\$6.75
<a href="#">SCE-8086CHNF</a>	\$88.00	8.38 x 8.39 x 6.20 [213 x 213 x 157]	<a href="#">PDF</a>	<a href="#">SCE-8P8</a>	\$6.75
<a href="#">SCE-1008CHSNF*</a>	\$94.00	8.39 x 10.38 x 4.20 [213 x 264 x 107]	<a href="#">PDF</a>	<a href="#">SCE-10P8</a>	\$8.00
<a href="#">SCE-1008CHNF</a>	\$89.00	10.38 x 8.39 x 4.20 [264 x 213 x 107]	<a href="#">PDF</a>	<a href="#">SCE-10P8</a>	\$8.00
<a href="#">SCE-10086CHNF</a>	\$102.00	10.38 x 8.39 x 6.20 [264 x 213 x 157]	<a href="#">PDF</a>	<a href="#">SCE-10P8</a>	\$8.00
<a href="#">SCE-10106CHNF</a>	\$104.00	10.38 x 10.39 x 6.20 [264 x 264 x 157]	<a href="#">PDF</a>	<a href="#">SCE-10P10</a>	\$9.25
<a href="#">SCE-1210CHSNF*</a>	\$115.00	10.39 x 12.38 x 5.20 [264 x 314 x 132]	<a href="#">PDF</a>	<a href="#">SCE-12P10</a>	\$10.75
<a href="#">SCE-12064CHNF</a>	\$82.00	12.38 x 6.39 x 4.20 [314 x 162 x 107]	<a href="#">PDF</a>	<a href="#">SCE-12P6</a>	\$7.50
<a href="#">SCE-1210CHNF</a>	\$112.00	12.38 x 10.39 x 5.20 [314 x 264 x 132]	<a href="#">PDF</a>	<a href="#">SCE-12P10</a>	\$10.75
<a href="#">SCE-12106CHNF</a>	\$118.00	12.38 x 10.39 x 6.20 [314 x 264 x 157]	<a href="#">PDF</a>	<a href="#">SCE-12P10</a>	\$10.75
<a href="#">SCE-12108CHNF</a>	\$127.00	12.38 x 10.39 x 8.20 [314 x 264 x 208]	<a href="#">PDF</a>	<a href="#">SCE-12P10</a>	\$10.75
<a href="#">SCE-1212CHNF</a>	\$130.00	12.38 x 12.39 x 6.20 [314 x 315 x 157]	<a href="#">PDF</a>	<a href="#">SCE-12P12</a>	\$12.50
<a href="#">SCE-1412CHSNF*</a>	\$152.00	12.39 x 14.38 x 6.20 [315 x 365 x 157]	<a href="#">PDF</a>	<a href="#">SCE-14P12</a>	\$14.00
<a href="#">SCE-14086CHNF</a>	\$112.00	14.38 x 8.39 x 6.20 [365 x 213 x 157]	<a href="#">PDF</a>	<a href="#">SCE-14P8</a>	\$10.25
<a href="#">SCE-1412CHNF</a>	\$145.00	14.38 x 12.39 x 6.20 [365 x 315 x 157]	<a href="#">PDF</a>	<a href="#">SCE-14P12</a>	\$14.00
<a href="#">SCE-14128CHNF</a>	\$153.00	14.38 x 12.39 x 8.20 [365 x 315 x 208]	<a href="#">PDF</a>	<a href="#">SCE-14P12</a>	\$14.00
<a href="#">SCE-1614CHSNF*</a>	\$178.00	14.39 x 16.38 x 6.20 [366 x 416 x 157]	<a href="#">PDF</a>	<a href="#">SCE-16P14</a>	\$27.50
<a href="#">SCE-16106CHNF</a>	\$132.00	16.38 x 10.39 x 6.20 [416 x 264 x 157]	<a href="#">PDF</a>	<a href="#">SCE-16P10</a>	\$13.75
<a href="#">SCE-1614CHNF</a>	\$169.00	16.38 x 14.39 x 6.20 [416 x 366 x 157]	<a href="#">PDF</a>	<a href="#">SCE-16P14</a>	\$27.50
<a href="#">SCE-16148CHNF</a>	\$185.00	16.38 x 14.39 x 8.20 [416 x 366 x 208]	<a href="#">PDF</a>	<a href="#">SCE-16P14</a>	\$27.50
<a href="#">SCE-161410CHNF</a>	\$194.00	16.38 x 14.39 x 10.20 [416 x 366 x 259]	<a href="#">PDF</a>	<a href="#">SCE-16P14</a>	\$27.50

Note: \*Part numbers containing an S are hinged on the short side.  
Dimensions in inches [millimeters].