

# Enclosure Accessories

## Deep-Hinged Doors



**SCE-HA1010LG**

Designed to house electrical controls, instruments, and components used in an indoor or outdoor environment to provide a degree of protection for the equipment inside the enclosure against ingress of solid foreign objects (falling dirt); and provide a degree of protection with respect to the harmful effects on the equipment due to the ingress of water (rain, sleet, snow). ELJ hinges. Black, mini 1/4-turn latches Gasket and hardware included.

### Listings

- Carbon Steel:
  - NEMA Type 3R, 4, 12, and 13
  - UL Listed Type 3R, 4 & 12 [File E69392]
- Stainless Steel:
  - NEMA Type 3R, 4, 4X, 12, and 13
  - UL Listed Type 3R, 4, 4X, 12, and 13 [File E69392]

### Shipping Schedule

Same day	1 - 15 days
----------	-------------

Color indicates shipping lead time in business days.

### Deep-Hinged Doors

<i>RAL7035</i>	<i>ANSI 61</i>	<i>White</i>	<i>Price</i>	<i>304 Stainless Steel</i>	<i>Price</i>	<i>Size HxWxD</i>	<i>Drawing Link</i>
<a href="#"><u>SCE-HA1010LG</u></a>	<a href="#"><u>SCE-HA1010</u></a>	<a href="#"><u>SCE-HA1010-05</u></a>	\$271.00	<a href="#"><u>SCE-HA1010SS</u></a>	\$619.00	10.00 x 10.00 x 2.63 [254 x 254 x 67]	<a href="#"><u>PDF</u></a>
—	<a href="#"><u>SCE-HA1014</u></a>	—	\$286.00	<a href="#"><u>SCE-HA1014SS</u></a>	\$618.00	10.00 x 14.00 x 2.63 [254 x 356 x 67]	<a href="#"><u>PDF</u></a>
<a href="#"><u>SCE-HA1212LG</u></a>	<a href="#"><u>SCE-HA1212</u></a>	<a href="#"><u>SCE-HA1212-05</u></a>	\$294.00	<a href="#"><u>SCE-HA1212SS</u></a>	\$647.00	12.00 x 12.00 x 2.63 [305 x 305 x 67]	<a href="#"><u>PDF</u></a>
—	<a href="#"><u>SCE-HA1216</u></a>	—	\$309.00	<a href="#"><u>SCE-HA1216SS</u></a>	\$668.00	12.00 x 16.00 x 2.63 [305 x 406 x 67]	<a href="#"><u>PDF</u></a>
	<a href="#"><u>SCE-HA1418</u></a>		\$348.00	<a href="#"><u>SCE-HA1418SS</u></a>	\$887.00	14.00 x 18.00 x 2.63 [356 x 457 x 67]	<a href="#"><u>PDF</u></a>
	<a href="#"><u>SCE-HA1620</u></a>		\$380.00	<a href="#"><u>SCE-HA1620SS</u></a>	\$822.00	16.00 x 20.00 x 2.63 [406 x 508 x 67]	<a href="#"><u>PDF</u></a>
<a href="#"><u>SCE-HA1814LG</u></a>	<a href="#"><u>SCE-HA1814</u></a>	—	\$348.00	<a href="#"><u>SCE-HA1814SS</u></a>	\$887.00	18.00 x 14.00 x 2.63 [457 x 356 x 67]	<a href="#"><u>PDF</u></a>


Note: Dimensions in inches [millimeters].

# Enclosure Accessories

## Deep-Hinged Doors with Windows



Your Enclosure Source®

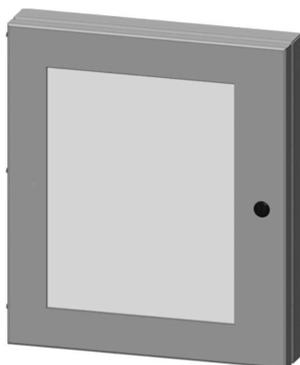

Designed to mount on the exterior of an enclosure to provide protection for controls with easy access. ELJ hinges. Black, mini 1/4-turn latches UV stable Polycarbonate viewing window. Gasket and hardware included. Made of heavy gauge carbon steel and powder coated.

"SS" parts made of heavy gauge stainless steel Type 304 with #4 brushed finish. Recommend use as Type 3R rating in full outdoor exposure and extreme weather environments – the addition of ventilation is necessary to handle the large negative pressure differential caused in a tightly sealed enclosure in extreme weather conditions. Temperatures that may exceed 140°F, such as outdoor in direct sunlight should be evaluated, shading or sun shield may be necessary.

### Listings

- NEMA Type 3R, 12, & 13
- UL Recognized Type 3R & 12

[SCE-HWK1212](#)

### Shipping Schedule

Same day      1 - 15 days

Color indicates shipping lead time in business days.

Deep-Hinged Doors with Windows								
ANSI 61	RAL 7035	Price	304 Stainless Steel	Price	Overall Size HxWxD	Window Size HxW	Maximum Cut-Out Size HxW	Drawing Link
<a href="#">SCE-HWK1014</a>	—	\$312.00	<a href="#">SCE-HWK1014SS</a>	\$674.00	10.00 x 14.00 x 2.63 [254 x 356 x 67]	6.00 x 9.38 [152 x 238]	7.50 x 11.50 [191 x 292]	<a href="#">PDF</a>
<a href="#">SCE-HWK1212</a>	<a href="#">SCE-HWK1212LG</a>	\$339.00	<a href="#">SCE-HWK1212SS</a>	\$700.00	12.00 x 12.00 x 2.63 [305 x 305 x 67]	8.00 x 7.38 [203 x 187]	9.50 x 9.50 [241 x 241]	<a href="#">PDF</a>
<a href="#">SCE-HWK1216</a>	—	\$380.00	<a href="#">SCE-HWK1216SS</a>	\$822.00	12.00 x 16.00 x 2.63 [305 x 406 x 67]	8.00 x 11.38 [203 x 289]	9.50 x 13.50 [241 x 343]	<a href="#">PDF</a>
<a href="#">SCE-HWK1312</a>	—	\$355.00	—	—	13.00 x 12.00 x 2.63 [330 x 305 x 67]	8.00 x 7.38 [203 x 187]	10.50 x 9.50 [267 x 241]	<a href="#">PDF</a>
<a href="#">SCE-HWK1418</a>	—	\$393.00	<a href="#">SCE-HWK1418SS</a>	\$850.00	14.00 x 18.00 x 2.63 [356 x 457 x 67]	10.00 x 13.38 [254 x 340]	11.50 x 15.50 [292 x 394]	<a href="#">PDF</a>
<a href="#">SCE-HWK1620</a>	—	\$437.00	<a href="#">SCE-HWK1620SS</a>	\$943.00	16.00 x 20.00 x 2.63 [406 x 508 x 67]	12.00 x 15.38 [305 x 391]	13.50 x 17.50 [343 x 445]	<a href="#">PDF</a>
<a href="#">SCE-HWK1814</a>	<a href="#">SCE-HWK1814LG</a>	\$393.00	<a href="#">SCE-HWK1814SS</a>	\$950.00	18.00 x 14.00 x 2.63 [457 x 356 x 67]	14.00 x 9.38 [356 x 238]	15.50 x 11.50 [394 x 292]	<a href="#">PDF</a>
<a href="#">SCE-HWK2218</a>	<a href="#">SCE-HWK2218LG</a>	\$475.00	<a href="#">SCE-HWK2218SS</a>	\$1,145.00	22.00 x 18.00 x 2.63 [559 x 457 x 67]	18.00 x 13.38 [457 x 340]	19.50 x 15.50 [495 x 394]	<a href="#">PDF</a>
<a href="#">SCE-HWK2228</a>	<a href="#">SCE-HWK2228LG</a>	\$543.00	<a href="#">SCE-HWK2228SS</a>	\$1,416.00	22.00 x 28.00 x 2.63 [559 x 711 x 67]	(2) 18.00 x 10.56 [457 x 268]	19.50 x 25.50 [495 x 648]	<a href="#">PDF</a>
<a href="#">SCE-HWK2822</a>	<a href="#">SCE-HWK2822LG</a>	\$543.00	<a href="#">SCE-HWK2822SS</a>	\$1,416.00	28.00 x 22.00 x 2.63 [711 x 559 x 67]	(2) 10.88 x 17.38 [276 x 441]	25.50 x 19.50 [648 x 495]	<a href="#">PDF</a>

Note: Dimensions in inches [millimeters].

# Enclosure Accessories

## Hinges and Hinge Pins



Standard replacement hinges for standard Saginaw enclosures. Includes hinge, pin, and clip.



SCE-3916



SCE-ELJHINGE



SCE-101670




SCE-101221

Shipping Schedule	
Same day	1 - 15 days
Color indicates shipping lead time in business days.	

Replacement Hinges					
Carbon Steel	Price	304 Stainless Steel	Price	Description	Qty
<u>SCE-3916</u>	\$13.75	<u>SCE-3916SS</u>	\$29.00	large concealed hinge	1
<u>SCE-3918</u>	\$22.00	<u>SCE-3918SS</u>	\$53.00	small concealed hinge	1
<u>SCE-ELJHINGE</u>	\$7.50	—	—	ELJ hinge	1
<u>SCE-101670</u>	\$14.00	—	—	retaining clip for concealed hinge	1
<u>SCE-101221</u>	\$35.50	—	—	large hinge pin	20
<u>SCE-101226</u>	\$67.00	—	—	small hinge pin	20

# Enclosure Accessories

## Enclosure Windows

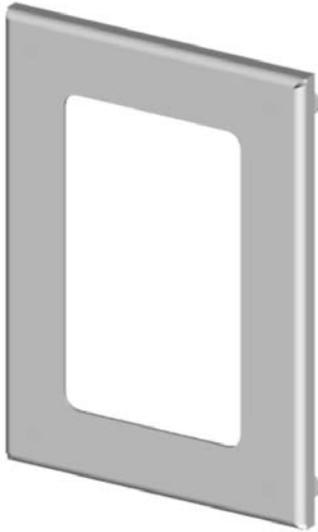

SCE-PWK53NF

Designed for use on most SCE Type 4, 4X and 12 enclosures. Includes frame, window, oil-resistant gasket, and mounting hardware. Installed by making a cutout in the enclosure and fastening the window and frame in place.

The window is 0.25" UV stable polycarbonate material. Made of heavy gauge steel and powder coated ANSI 61 gray. "SS" kits are made of Type 304 stainless with #4 brushed finish. Recommend use as Type 3R rating in full outdoor exposure and extreme weather environments.

### Listings

- NEMA Type 1, 3R, 4, 4X & 12
- UL Recognized Type 1, 3R & 12

### Shipping Schedule

Same day	1 - 15 days
----------	-------------

Color indicates shipping lead time in business days.

### UV-Resistant Window Kits

Carbon Steel	Price	304 Stainless Steel	Price	Window Size HxW	Drawing Link
<a href="#">SCE-PWK53NF</a>	\$132.00	<a href="#">SCE-PWK53NFSS</a>	\$198.00	5.25 x 3.25 [133 x 83]	<a href="#">PDF</a>
<a href="#">SCE-PWK63NF</a>	\$145.00	—	—	6.55 x 2.85 [166 x 72]	<a href="#">PDF</a>
<a href="#">SCE-PWK95NF</a>	\$158.00	<a href="#">SCE-PWK95NFSS</a>	\$239.00	9.25 x 5.75 [235 x 146]	<a href="#">PDF</a>
<a href="#">SCE-PWK138NF</a>	\$201.00	<a href="#">SCE-PWK138NFSS</a>	\$304.00	13.25 x 8.25 [337 x 210]	<a href="#">PDF</a>
<a href="#">SCE-PWK1711NF</a>	\$277.00	<a href="#">SCE-PWK1711NFSS</a>	\$399.00	17.25 x 11.25 [438 x 286]	<a href="#">PDF</a>
<a href="#">SCE-PWK2315NF</a>	\$341.00	<a href="#">SCE-PWK2315NFSS</a>	\$516.00	23.25 x 15.25 [591 x 387]	<a href="#">PDF</a>
<a href="#">SCE-PWK2919NF</a>	\$508.00	<a href="#">SCE-PWK2919NFSS</a>	\$765.00	29.25 x 19.25 [743 x 489]	<a href="#">PDF</a>

Note: Dimensions in inches [millimeters].

# Enclosure Accessories

## Enclosure Windows



SCE-AW1208SG

Designed for use on most SCE Type 4, 4X and 12 enclosures. Includes frame, window, oil-resistant gasket, and mounting hardware. Installed by making a cutout in the enclosure and fastening the window and frame in place. For technical information, consult our Installation

Manual. The window is made of laminated safety glass for easier clean up and an aluminum

extruded frame. Recommend use as Type 3R rating in full outdoor exposure and extreme weather

environments.

For more details see Design Considerations When Specifying Your Enclosure on our website.

### Listings

- NEMA Type 1, 3R, 4, 4X & 12
- UL Recognized Type 1, 3R & 12

### Shipping Schedule

Same day	1 - 15 days
----------	-------------

Color indicates shipping lead time in business days.

### Extruded Aluminum Safety Glass UV-Resistant Windows

Part Number	Price	Window Size HxW	Drawing Link
<a href="#">SCE-AW1208SG</a>	\$362.00	12.00 x 8.00 [305 x 203]	<a href="#">PDF</a>
<a href="#">SCE-AW1812SG</a>	\$463.00	18.00 x 12.00 [457 x 305]	<a href="#">PDF</a>
<a href="#">SCE-AW2016SG</a>	\$552.00	20.00 x 16.00 [508 x 406]	<a href="#">PDF</a>
<a href="#">SCE-AW2620SG</a>	\$675.00	26.00 x 20.00 [660 x 508]	<a href="#">PDF</a>
<a href="#">SCE-AW6020SG</a>	Retired	60.00 x 20.00 [1524 x 508]	<a href="#">PDF</a>

Note: Dimensions in inches [millimeters].