

# NEMA 3R Painted Galvannealed Steel Single-Door Wall-Mount



Your Enclosure Source®



## Applications

Designed to house electrical controls, instruments, and components in an outdoor environment. Protects against rain, sleet and snow.

## Construction

- 14-gauge, 16-gauge, or 18-gauge galvannealed steel
- Concealed hinges
- Spot weld construction
- Rain cap
- Mounting holes in back of enclosure
- Provisions for subpanel
- Doors open 180°
- Black, 1/4-turn latch with padlocking wing-knobs
- Poured-in-place oil- and water-resistant gasket
- Ground studs on door and body
- 3/8-16 grounding kit
- Subpanel mounting hardware included

Note: Optional mounting straps or mounting foot kits available.

## Finish


- ANSI 61 gray powder coated inside and out
- Optional subpanels are powder coated white.

## Listings

- NEMA Type 3R
- cULus Listed Type 3R [File E69392]
- IEC 60529 IP32



## Dimensions

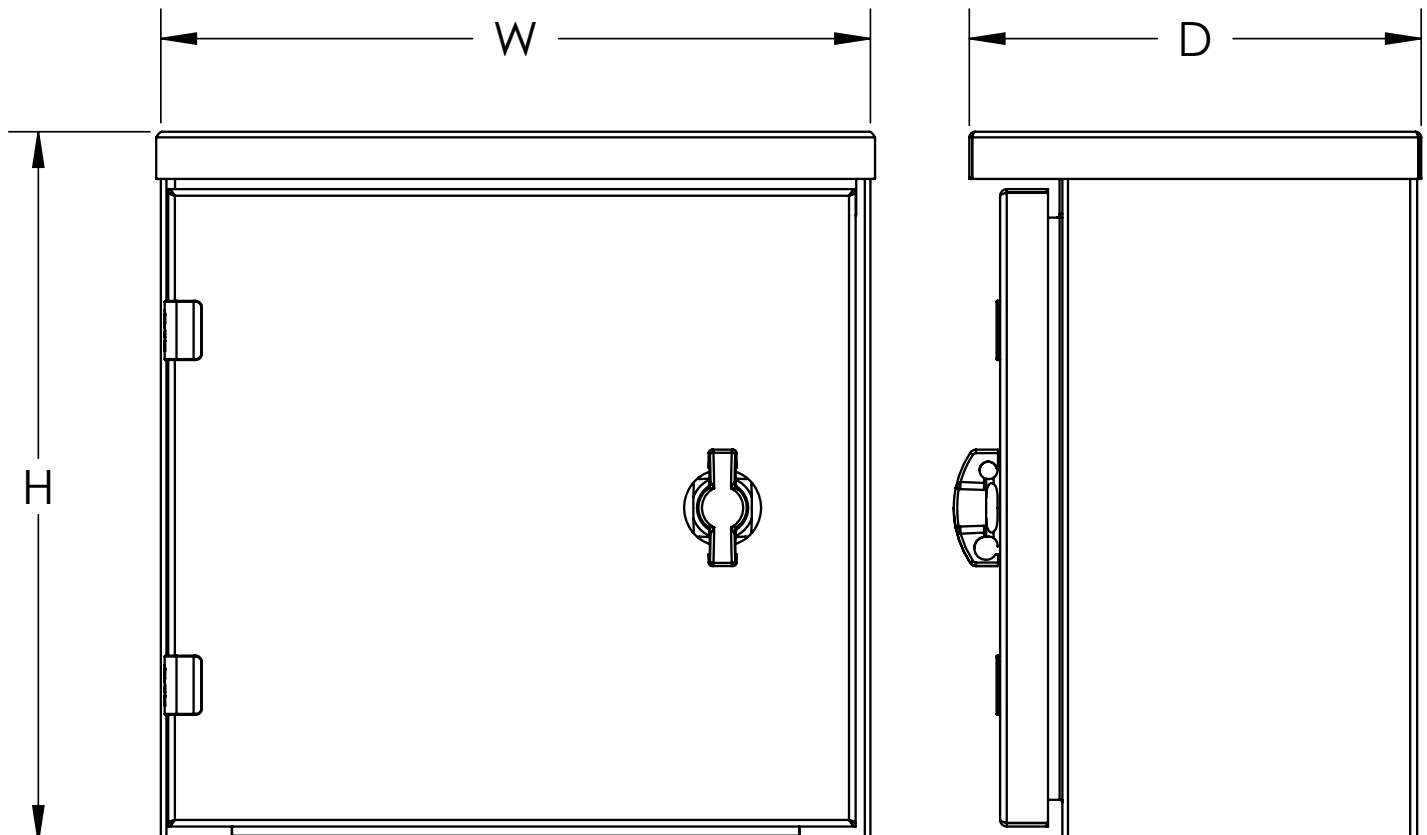

# NEMA 3R Painted Galvannealed Steel Single-Door Wall-Mount



Your Enclosure Source®

## Shipping Schedule

Same day

1 - 15 days

Color indicates shipping lead time in business days.

## NEMA 3 Painted Galvannealed Steel Single-Door Wall-Mount

Part Number	Price	Size HxWxD	Drawing Link	Optional Subpanel	Price
<a href="#">SCE-12R1206LP</a>	\$110.00	12.00 x 12.20 x 7.70 [305 x 310 x 196]	<a href="#">PDF</a>	<a href="#">SCE-12DLP12</a>	\$19.00
<a href="#">SCE-12R1208LP</a>	\$116.00	12.00 x 12.20 x 9.70 [305 x 310 x 246]	<a href="#">PDF</a>	<a href="#">SCE-12DLP12</a>	\$19.00
<a href="#">SCE-16R1206LP</a>	\$143.00	16.00 x 12.20 x 7.70 [406 x 310 x 196]	<a href="#">PDF</a>	<a href="#">SCE-16P12</a>	\$20.50
<a href="#">SCE-16R1208LP</a>	\$150.00	16.00 x 12.20 x 9.70 [406 x 310 x 246]	<a href="#">PDF</a>	<a href="#">SCE-16P12</a>	\$20.50
<a href="#">SCE-20R1606LP</a>	\$193.00	20.00 x 16.20 x 7.70 [508 x 411 x 196]	<a href="#">PDF</a>	<a href="#">SCE-20P16</a>	\$42.00
<a href="#">SCE-20R1608LP</a>	\$202.00	20.00 x 16.20 x 9.70 [508 x 411 x 246]	<a href="#">PDF</a>	<a href="#">SCE-20P16</a>	\$42.00
<a href="#">SCE-24R2006LP</a>	\$295.00	24.00 x 20.20 x 7.70 [610 x 513 x 196]	<a href="#">PDF</a>	<a href="#">SCE-24P20</a>	\$63.00
<a href="#">SCE-24R2008LP</a>	\$309.00	24.00 x 20.20 x 9.70 [610 x 513 x 246]	<a href="#">PDF</a>	<a href="#">SCE-24P20</a>	\$63.00
<a href="#">SCE-24R2012LP</a>	\$332.00	24.00 x 20.20 x 13.70 [610 x 513 x 348]	<a href="#">PDF</a>	<a href="#">SCE-24P20</a>	\$63.00
<a href="#">SCE-24R2016LP</a>	\$360.00	24.00 x 20.20 x 17.70 [610 x 513 x 450]	<a href="#">PDF</a>	<a href="#">SCE-24P20</a>	\$63.00
<a href="#">SCE-24R2408LP</a>	\$335.00	24.00 x 24.20 x 9.70 [610 x 615 x 246]	<a href="#">PDF</a>	<a href="#">SCE-24P24</a>	\$74.00
<a href="#">SCE-24R2412LP</a>	\$359.00	24.00 x 24.20 x 13.70 [610 x 615 x 348]	<a href="#">PDF</a>	<a href="#">SCE-24P24</a>	\$74.00
<a href="#">SCE-24R2416LP</a>	\$388.00	24.00 x 24.20 x 17.70 [610 x 615 x 450]	<a href="#">PDF</a>	<a href="#">SCE-24P24</a>	\$74.00
<a href="#">SCE-30R2408LP</a>	\$408.00	30.00 x 24.20 x 9.70 [762 x 615 x 246]	<a href="#">PDF</a>	<a href="#">SCE-30P24</a>	\$88.00
<a href="#">SCE-30R2412LP</a>	\$432.00	30.00 x 24.20 x 13.70 [762 x 615 x 348]	<a href="#">PDF</a>	<a href="#">SCE-30P24</a>	\$88.00
<a href="#">SCE-30R2416LP</a>	\$463.00	30.00 x 24.20 x 17.70 [762 x 615 x 450]	<a href="#">PDF</a>	<a href="#">SCE-30P24</a>	\$88.00
<a href="#">SCE-36R2408LP</a>	\$598.00	36.00 x 24.20 x 9.70 [914 x 615 x 246]	<a href="#">PDF</a>	<a href="#">SCE-36P24</a>	\$105.00
<a href="#">SCE-36R2412LP</a>	\$626.00	36.00 x 24.20 x 13.70 [914 x 615 x 348]	<a href="#">PDF</a>	<a href="#">SCE-36P24</a>	\$105.00
<a href="#">SCE-36R2416LP</a>	\$653.00	36.00 x 24.20 x 17.70 [914 x 615 x 450]	<a href="#">PDF</a>	<a href="#">SCE-36P24</a>	\$105.00
<a href="#">SCE-36R3008LP</a>	\$635.00	36.00 x 30.20 x 9.70 [914 x 767 x 246]	<a href="#">PDF</a>	<a href="#">SCE-36P30</a>	\$141.00
<a href="#">SCE-36R3012LP</a>	\$665.00	36.00 x 30.20 x 13.70 [914 x 767 x 348]	<a href="#">PDF</a>	<a href="#">SCE-36P30</a>	\$141.00
<a href="#">SCE-36R3016LP</a>	\$692.00	36.00 x 30.20 x 17.70 [914 x 767 x 450]	<a href="#">PDF</a>	<a href="#">SCE-36P30</a>	\$141.00
<a href="#">SCE-42R3012LP</a>	\$750.00	42.00 x 30.20 x 13.70 [1067 x 767 x 348]	<a href="#">PDF</a>	<a href="#">SCE-42P30</a>	\$162.00
<a href="#">SCE-42R3016LP</a>	\$789.00	42.00 x 30.20 x 17.70 [1067 x 767 x 450]	<a href="#">PDF</a>	<a href="#">SCE-42P30</a>	\$162.00

Note: Dimensions in inches [millimeters].