



Product availability: Stock - Normally stocked in distribution facility



Main

Range	Linergy
Product name	FT
Device short name	GV2G
Product or component type	Comb busbar
Accessory / separate part category	Connection accessory
Poles description	3P
Range compatibility	TeSys D TeSys GV2 TeSys K TeSys U
Number of tap-offs	3
[I _{th}] conventional free air thermal current	63 A
Connection pitch	2.13 in (54 mm)

Complementary

Mounting location	On terminal
[U _i] rated insulation voltage	690 V
Length	5.98 in (152 mm)
Net weight	0.13 lb(US) (0.06 kg)

Ordering and shipping details

Category	22367 - MANUAL STR PROTECTOR - GV2
Discount Schedule	I11
GTIN	00785901490098
Package weight(Lbs)	0.06 kg (0.14 lb(US))
Returnability	Yes
Country of origin	RO


Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS Declaration
Environmental Disclosure	Product Environmental Profile
Circularity Profile	No need of specific recycling operations

Contractual warranty

Warranty	18 months
----------	-----------

Sets of Busbars GV2G345 and GV2G354

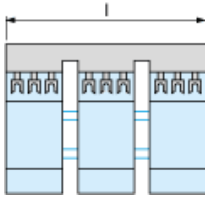

	l
GV2G345 (3 x 45 mm)	134
GV2G354 (3 x 54 mm)	152