

METAL CONTINUOUS WASTES – CENTER OUTLET

/// 240-30 SERIES, 240-31 SERIES

SPECIFICATION

Tomahawk Metal Continuous Wastes Center Outlet are intended to provide accessible and replaceable tube and fittings to convey domestic waste from fixtures to the drain, waste and vent (DWV) system. Tomahawk Metal Continuous Wastes Center Outlet shall meet or exceed ASME standard A112.18.2.

MATERIALS

Metal

Finish: chrome

FEATURES

- supplied with baffle tee

DIMENSIONS

*Tomahawk specifications in US customary units are approximate and are provided for reference only.

	-306116C	-306121C	-3062161C	-306216C
A: length	16"	21"	21"	16"
B: height	7-1/2"	7-1/2"	7-1/2"	7-1/2"
C: center to outlet	8"	10-1/2"	10-1/2"	8"
D: bend height	2"	2"	2"	2"
E: gauge	22ga	22ga	20ga	20ga

	-3063161C	-316116C	-316216C
A: length	16"	16"	16"
B: height	7-1/2"	8"	8"
C: center to outlet	8"	8"	8"
D: bend height	2"	2-1/2"	2-1/2"
E: gauge	17ga	22ga	20ga



ITEM # SUBMITTED	_____
JOB NAME	_____
LOCATION	_____
ENGINEER	_____
CONTRACTOR	_____
PO#	_____ TAG _____



240-306116C04



240-316116C04

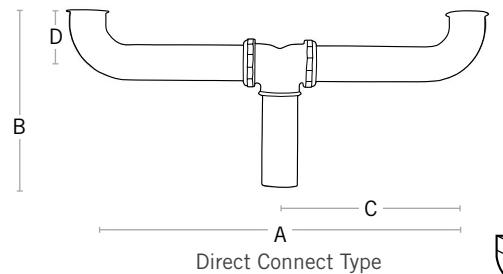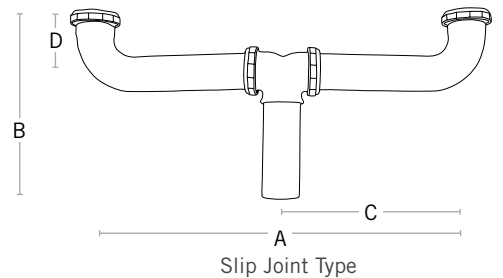

Create Item Number

240-A6BC1C04

e.g. **240-3162161C04**: center-outlet direct connect continuous waste (with baffle), 20ga, 1-1/2" x 16", chrome, 1/bx

ITEM A

30 = center-outlet slip joint connect continuous waste (with baffle)

31 = center-outlet direct connect continuous waste (with baffle)

GAUGE B

1 = 22ga

2 = 20ga

3 = 17ga

LENGTH C

16 = 16"

21 = 21"



*Not all combinations available. Contact your local rep to confirm availability.