

OUTLET BOX

» 696 SERIES

OxBox™

ITEM # SUBMITTED	_____
JOB NAME	_____
LOCATION	_____
ENGINEER	_____
CONTRACTOR	_____
PO#	_____ TAG _____

SPECIFICATION

Sioux Chief 696 series OxBox single hole boxes shall be used where necessary in accessible plumbing applications. The boxes shall provide an appropriately sized hole for 1½" and 2" drain, waste, and vent (DWV) lines. Boxes accept existing frames for OxBox product. Boxes incorporate four mounting tabs, two nail-ways, and a support bar channel used with common, galvanized, flat brackets. Boxes can be clipped together using a 696-BC galvanized box clip in any iteration for use as necessary.

MATERIAL

ABS

SAFE WORKING TEMPERATURE

Melting point: 200°F


Working temperature: 150°F

DIMENSIONS

A: rough-in box inner width	4"
B: rough-in box overall depth	3½"
C: rough-in box inner height	5½"
	696-6 696-7
D: hole diameter	1.915" 2.390"



696-6

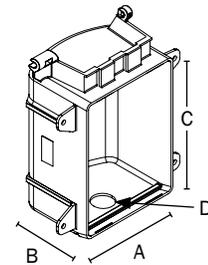

Create Item Number

696-A

e.g. 696-6: outlet box with 1.915" diameter hole

HOLE SIZE A

6 = 1.915" hole for 1½" DWV pipe

7 = 2.390" hole for 2" DWV pipe