

CODE NUMBER

3917816

DESCRIPTION


3.5 gpf, Polished Chrome Finish, 1" Flush Connection, Fixture Connection , Single Flush, Hardwired, 24V, Royal® Exposed Urinal Flushometer.

DETAILS

- Flush Volume: 3.5 gpf (13.2 Lpf)
- Finish: Polished Chrome (CP)
- Power Type: Hardwired (HW)
- Valve: Diaphragm
- Valve Body Material: Semi-red Brass
- Fixture Type: Urinal
- Flush Connection: 1" (V)
- Voltage: 24V

FEATURES

- PERMEX synthetic rubber diaphragm with Dual Filtered Fixed Bypass
- Valve body, Cover, Tailpiece and Control Stop shall be in compliance with ASTM Alloy Classification for Semi-Red Brass
- Valve shall be in compliance to the applicable sections of ASSE 1037
- Model ES flushometers are activated remotely by an electric push button (not included). "ES" flushometers offer solutions for installations that require automatic, remote or other control requirements

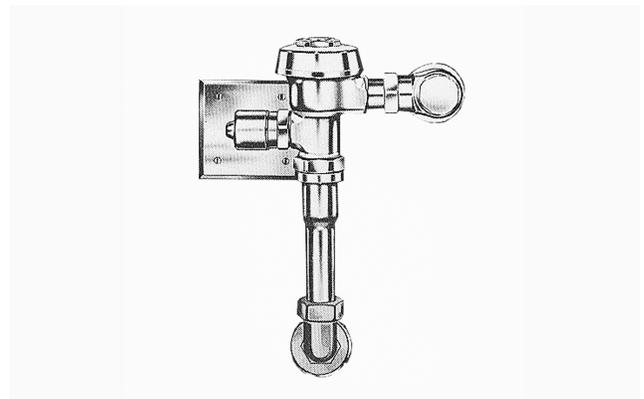

COMPLIANCES & CERTIFICATIONS



(BAA Compliant, BABAA Compliant, UPC Certified)

ELECTRICAL SPECIFICATIONS

- Transformers (specify separately):
 - 0345154
 - 0345999

DOWNLOADS

- [Additional Downloads](#)

NOTES


All information contained within this document subject to change without notice.

Looking for other variations of the Royal 853 product? [View the general spec sheet with all options.](#)

WARRANTY

[View Warranty Information](#)

ROUGH-IN

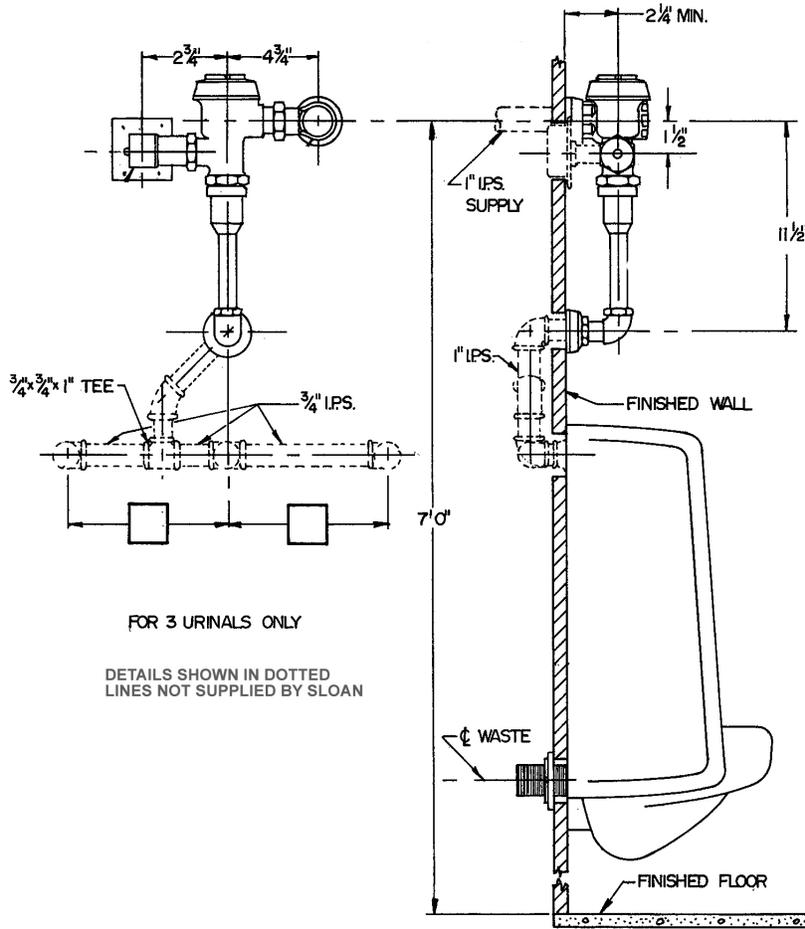

Sloan 10500 Seymour Ave, Franklin Park, IL 60131
Phone: 800.982.5839 • Fax: 800.447.8329 • sloan.com