

Accessories

External handle



Front operation I - 0, 3/4 poles

Rating (A)	Handle	Handle color	Nema degree of protection	Reference
100 ... 400	S2 type	Black	1, 3R, 12	142F 2111 ⁽¹⁾
100 ... 400	S2 type	Red/Yellow	1, 3R, 12	142G 2111 ⁽¹⁾
100 ... 400	S2 type	Black	4, 4X	143D 3111 ⁽¹⁾
100 ... 400	S2 type	Red/Yellow	4, 4X	142E 2111 ⁽¹⁾
600	S4 type	Black	4, 4X	144D 3111 ⁽¹⁾
600	S4 type	Red/Yellow	4, 4X	144E 3111 ⁽¹⁾

(1) Defeatable handle.

Front operation I - 0, 6/8 poles

Rating (A)	Handle	Handle color	Nema degree of protection	Reference
400	S3 type	Black	4, 4X	144D 3111 ⁽¹⁾
400	S3 type	Red/Yellow	4, 4X	144E 3111 ⁽¹⁾

(1) Defeatable handle.

Front operation I - 0 heavy duty, 3/4 poles

Rating (A)	Handle	Handle color	Nema degree of protection	Reference
100 ... 400	S2 type	Black	4, 4X	144D 3111 ⁽¹⁾
100 ... 400	S2 type	Red/Yellow	4, 4X	144E 3111 ⁽¹⁾

(1) With metallic padlocking lever.
(2) Defeatable handle.

Use

The interlocking function of the front external handle prevents the user from opening the door of the enclosure when the switch is in the "ON" position (if the handle is door mounted only). Opening the door when the switch is on "ON" position is possible by defeating the locking function with the use of a tool (authorized persons only). The interlocking function is restored when the door is re-closed.

Front operation I - 0 heavy duty, 6/8 poles

Rating (A)	Handle	Handle color	Nema degree of protection	Reference
400	S3 type	Black	4, 4X	144D 3111 ⁽¹⁾
400	S3 type	Red/Yellow	4, 4X	144E 3111 ⁽¹⁾
600	V1 type	Black	4, 4X	2799 7145 ⁽¹⁾

(1) With metallic padlocking lever.
(2) Defeatable handle.

S type handle raiser




Use
Handle raiser.

Dimensions
Adds 12 mm to the depth.

Color	Nema degree of protection	To be ordered in multiples of	Reference
Black	1, 3R, 12	10	1493 0000

Alternative S type handle cover colours

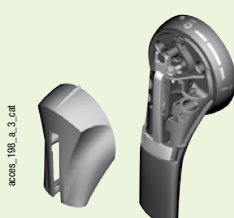

Use
For handle S2, S3 and S4.

Other colours: consult us.

Handle color	Handle	To be ordered in multiples of	Reference
Light grey	S2, S3 type	50	1401 0001
Dark grey	S2, S3 type	50	1401 0011
Light grey	S4 type	50	1401 0031
Dark grey	S4 type	50	1401 0041