

## Accessories

### Direct handle

| Rating (A)   | Colour | Handle type | Reference        |
|--------------|--------|-------------|------------------|
| 100 ... 400  | Black  | 1 lever     | 4199 <b>4012</b> |
| 600 ... 1200 | Black  | 2 lever     | 2799 <b>7042</b> |



access\_129\_a\_1\_cat

### External handle

| Rating (A)   | Handle type | Colour     | Nema type                | Lockable in 3 positions | Reference        |
|--------------|-------------|------------|--------------------------|-------------------------|------------------|
| 100 ... 200  | S2          | Black      | 4, 4X                    | no                      | 142D <b>2113</b> |
| 100 ... 200  | S2          | Red/Yellow | 4, 4X                    | no                      | 142E <b>2113</b> |
| 100 ... 200  | S2          | Black      | 1, 3R, 12                | no                      | 142F <b>2113</b> |
| 100 ... 200  | S2          | Red/Yellow | 1, 3R, 12                | no                      | 142G <b>2113</b> |
| 100 ... 200  | S2          | Black      | 4, 4X                    | yes                     | 142D <b>2813</b> |
| 100 ... 200  | S2          | Red/Yellow | 4, 4X                    | yes                     | 142E <b>2813</b> |
| 100 ... 200  | S2          | Black      | 1, 3R, 12                | yes                     | 142F <b>2813</b> |
| 100 ... 200  | S2          | Red/Yellow | 1, 3R, 12                | yes                     | 142G <b>2813</b> |
| 260 ... 600  | S3          | Black      | 4, 4X                    | no                      | 143D <b>3113</b> |
| 260 ... 600  | S3          | Red/Yellow | 4, 4X                    | no                      | 143E <b>3113</b> |
| 260 ... 600  | S3          | Black      | 1, 3R, 12                | no                      | 143F <b>3113</b> |
| 260 ... 600  | S3          | Red/Yellow | 1, 3R, 12                | no                      | 143G <b>3113</b> |
| 260 ... 600  | S3          | Black      | 4, 4X                    | yes                     | 143D <b>3813</b> |
| 260 ... 600  | S3          | Red/Yellow | 4, 4X                    | yes                     | 143E <b>3813</b> |
| 260 ... 600  | S3          | Black      | 1, 3R, 12                | yes                     | 143F <b>3813</b> |
| 260 ... 600  | S3          | Red/Yellow | 1, 3R, 12                | yes                     | 143G <b>3813</b> |
| 800 ... 1200 | S4          | Black      | 4, 4X                    | no                      | 144D <b>3113</b> |
| 800 ... 1200 | S4          | Black      | 1, 3R, 12                | no                      | 144E <b>3113</b> |
| 800 ... 1200 | S4          | Black      | 1, 3R, 12                | no                      | 144F <b>3113</b> |
| 800 ... 1200 | S4          | Red/Yellow | 1, 3R, 12                | no                      | 144G <b>3113</b> |
| 800 ... 1200 | S4          | Black      | 4, 4X                    | yes                     | 144D <b>3813</b> |
| 800 ... 1200 | S4          | Red/Yellow | 4, 4X                    | yes                     | 144E <b>3813</b> |
| 800 ... 1200 | S4          | Black      | 1, 3R, 12                | yes                     | 144F <b>3813</b> |
| 800 ... 1200 | S4          | Red/Yellow | 1, 3R, 12                | yes                     | 144G <b>3813</b> |
| 800 ... 1200 | S5          | Black      | 1, 3R, 12 <sup>(1)</sup> | no                      | 1453 <b>8113</b> |
| 800 ... 1200 | S5          | Red/Yellow | 1, 3R, 12 <sup>(1)</sup> | no                      | 1454 <b>8113</b> |
| 800 ... 1200 | V1          | Black      | 1, 3R, 12 <sup>(1)</sup> | no                      | 4199 <b>7149</b> |

(1) For 4, 4X please consult us.

### Use

The handle interlocking function prevents the user from opening the door of the enclosure when the switch is in the "ON" position.

Opening the door when the switch is in the "ON" position is possible by defeating the interlocking function (Not S5 and V handles) with the use of a tool (authorized persons only).

The interlocking function is restored when the door is re-closed.



access\_150\_a\_1\_cat



access\_151\_a\_1\_cat



access\_152\_a\_1\_cat




access\_296\_a\_2\_cat

### Shaft for external handle

| Rating (A)   | Handle type  | Length (in) | Length (mm) | Dimension X (in) | Dimension X (mm) | Reference        |
|--------------|--------------|-------------|-------------|------------------|------------------|------------------|
| 100 ... 200  | S2 type      | 7.9         | 200         | 10 ... 14.3      | 254 ... 362      | 1400 <b>1020</b> |
| 100 ... 200  | S2 type      | 12.6        | 320         | 10 ... 19        | 254 ... 482      | 1400 <b>1032</b> |
| 100 ... 200  | S2 type      | 15.7        | 400         | 10 ... 22.1      | 254 ... 562      | 1400 <b>1040</b> |
| 260 ... 400  | S3 type      | 7.9         | 200         | 12 ... 18.4      | 305 ... 467      | 1401 <b>1520</b> |
| 260 ... 400  | S3 type      | 12.6        | 320         | 12 ... 23.1      | 305 ... 587      | 1401 <b>1532</b> |
| 260 ... 400  | S3 type      | 15.7        | 400         | 12 ... 26.3      | 305 ... 667      | 1401 <b>1540</b> |
| 260 ... 400  | S3 type      | 7.9         | 200         | 20 ... 23.4      | 508 ... 594      | 1401 <b>1520</b> |
| 260 ... 400  | S3 type      | 12.6        | 320         | 20 ... 28.1      | 508 ... 714      | 1401 <b>1532</b> |
| 260 ... 400  | S3 type      | 15.7        | 400         | 20 ... 31.3      | 508 ... 794      | 1401 <b>1540</b> |
| 800 ... 1200 | S4 type      | 7.9         | 200         | 20 ... 23.4      | 508 ... 594      | 1401 <b>1520</b> |
| 800 ... 1200 | S4 type      | 12.6        | 320         | 20 ... 28.1      | 508 ... 714      | 1401 <b>1532</b> |
| 800 ... 1200 | S4 type      | 15.7        | 400         | 20 ... 31.3      | 508 ... 794      | 1401 <b>1540</b> |
| 800 ... 1200 | V1 / S5 type | 12.6        | 320         | 20 ... 28.1      | 508 ... 714      | 4199 <b>3018</b> |
| 800 ... 1200 | V1 / S5 type | 15.7        | 400         | 20 ... 31.3      | 508 ... 794      | 4199 <b>3019</b> |



access\_369\_a\_1\_cat

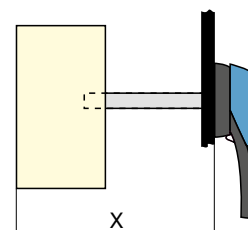

access\_202\_a\_1\_x\_cat