

Enclosed changeover switches

Motorised operation

RTSE - remote controlled from 40 to 3200 A

Single-phase ATyS M 3s in polycarbonate enclosure



atysm_201_a_1_cat

General characteristics

- From 40 to 160 A.
- Network 230 VAC [176-288 VAC] / 50 Hz/60 Hz [45 Hz-65 Hz].
- Protection degree: IP 55, IK08.
- Colour RAL 7035.
- Material: transparent cover, polycarbonate casing.
- Wall mounting: 4 holes on the rear of the enclosure.
- Flame resistant to 650°C.

References

Single-phase ATyS M 3s model (2P)

Rating (A)	Reference
40	1823 2004
63	1823 2006
80	1823 2008
100	1823 2010
125	1823 2012
160	1823 2016

Accessories

Customer fit

Description	Reference
Auxiliary contact ⁽¹⁾	1309 0001
Voltage sensing and power supply tap (2 per reference) ⁽¹⁾	1399 4006

⁽¹⁾ For more details please refer to the ATyS M section of this catalogue.



Auxiliary contact

Voltage tap



ATyS C30 control relay

ATyS C40 control relay


DPS

Factory fitted.

Description	Reference
ATyS C30 control relay ⁽¹⁾	1599 3030
ATyS C40 control relay ⁽¹⁾	1599 3040
Dual power supply ⁽¹⁾	1599 4001

⁽¹⁾ For more details please refer to the ATyS M section of this catalogue.

Dimensions

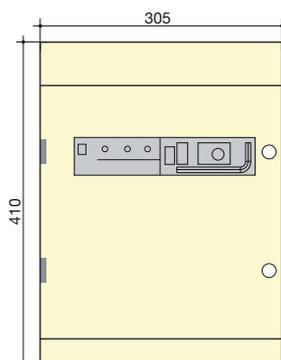

- Weight: 5.5 kg.
- Connection: recommended cable size (Cu): 25 to 70 mm² according to rating (maximum size of a cable: 70 mm²).

atysm_208_a_1_x_cat