

FUSERBLOC in polyester enclosure

■ Front operation

coff_319_a_2_x_cat



General characteristics

- Adapted to environments subject to chemical, dust, contamination and atmospheric corrosion risks.
- Operation handle: S-type black padlockable handle.
- Protection degree: IP55 / IK 10.
- Colour: RAL 7030.
- Closing plate: N/A.
- Material: glass fibre reinforced polyester.
- Coating: N/A.
- Wall mounting: 4 fixing lugs supplied, not mounted.
- Locking system: screw.
- Fuses supplied separately; please see the fuse section of this catalogue, or consult us.


References

| Rating (A) | Fuses NFC and DIN ⁽¹⁾ | Top/Bottom connection Reference | Bottom/Bottom connection Reference |
|------------|----------------------------------|---------------------------------|------------------------------------|
| 3 x 50 | 14 x 51 | 3117 3005 | 3117 3005 |
| 4 x 50 | 14 x 51 | 3117 4005 | 3117 4005 |
| 3 x 100 | 22 x 58 | 3117 3010 | 3127 3010 |
| 4 x 100 | 22 x 58 | 3117 4010 | 3127 4010 |
| 3 x 160 | 0 | 3117 3016 | 3127 3016 |
| 4 x 160 | 0 | 3117 4016 | 3127 4016 |
| 3 x 250 | 1 | 3117 3025 | 3127 3025 |
| 4 x 250 | 1 | 3117 4025 | 3127 4025 |
| 3 x 400 | 2 | 3117 3040 | 3127 3040 |
| 4 x 400 | 2 | 3117 4040 | 3127 4040 |

(1) Fuses supplied separately; please see the fuse section of this catalogue or consult us.

Dimensions

coff_114_d_1_gb_cat

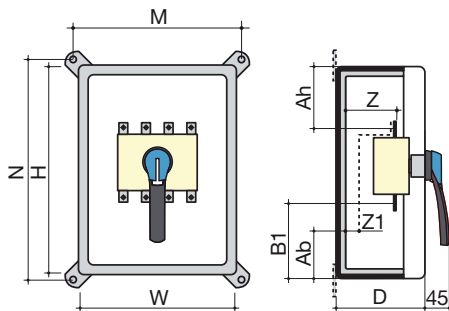

| Rating (A) | H x W x D (mm) | Connection cross-section (mm ²) | M (mm) | N (mm) | Z (mm) | Z1 (mm) | Top/Bottom connection | | | Bottom/Bottom connection | | |
|----------------------------------|-----------------|---|--------|--------|--------|---------|-----------------------|---------|-------------|--------------------------|---------|-------------|
| | | | | | | | Ah (mm) | B1 (mm) | Weight (kg) | Ab (mm) | B1 (mm) | Weight (kg) |
| 3 x 50 / 4 x 50 | 270 x 270 x 171 | 25 | 271 | 271 | 24 | | 86 | 86 | (1) | 90 | 90 | 3 |
| 3 x 100 / 4 x 100 | 360 x 270 x 171 | 95 | 271 | 361 | 20 | | 108 | 107 | 4 | (1) | (1) | (1) |
| 3 x 100 / 4 x 100 | 540 x 270 x 201 | 95 | (1) | (1) | (1) | (1) | (1) | (1) | (1) | (1) | (1) | (1) |
| 3 x 160 | 540 x 270 x 171 | 95 | 271 | 541 | 20 | | 220 | 180 | 6 | | | |
| 3 x 160 | 540 x 270 x 201 | 95 | 271 | 541 | 60 | 25 | | | | 220 | 320 | 8 |
| 4 x 160 | 540 x 360 x 171 | 95 | 361 | 541 | 20 | | 220 | 180 | 7 | | | |
| 4 x 160 | 540 x 360 x 201 | 95 | 361 | 541 | 60 | 25 | | | | 220 | 320 | 10 |
| 3 x 250 / 4 x 250 ⁽¹⁾ | | | | | | | | | | | | |
| 3 x 400 / 4 x 400 ⁽¹⁾ | | | | | | | | | | | | |

(1) Please consult us.