

# FUSERBLOC and high-speed fuses (UR)

Fuse combination switches

protection of power semi-conductors up to 1250 A

## External right side or front operation

Rating (A) / Fuse	No. of poles	Switch body	External front handle	External side handle	Shaft for external handle	Fuse protection covers	Auxiliary contact pre-break and position	Terminal shrouds
250 A / 1*	2 P	38U1 2024	S2 type Black IP55 1421 2111	S2 type Black IP55 1425 2111	320 mm 1400 1032	2 P 3990 2839 <sup>(1)</sup>		2 P 3998 2025
	3 P	38U1 3024						
400 A / 1	2 P	38U1 2039	S2 type Red IP65 1424 2111	S2 type Red/yellow IP65 1428 2111	320 mm 1400 1032	2 P 3990 2839 <sup>(1)</sup>		2 P 3998 2025
	3 P	38U1 3039						
500 A / 2	2 P	38U1 2050	S3 type Black IP65 1433 3111	S3 type Black IP65 1437 3111	320 mm 1400 1232	2 P 3890 2U63 <sup>(1)</sup>	1 contact NC 3999 0701	2 P 3898 2080
	3 P	38U1 3050						
630 A / 2	2 P	38U1 2063	S3 type Red/Yellow IP65 1434 3111	S3 type Black IP65 1437 3111	320 mm 1400 1232	2 P 3890 2U63 <sup>(1)</sup>	1 contact NO 3999 0702	2 P 3898 2080
	3 P	38U1 3063						
800 A / 3	2 P	38U1 2080	S3 type Red/Yellow IP65 1438 3111	S3 type Red/Yellow IP65 1438 3111	320 mm 1400 1232	2 P 3890 2U12 <sup>(1)</sup>		2 P 3898 2120
	3 P	38U1 3080						
1250 A / 3	2 P	38U1 2120	S4 type Black IP65 1443 3111	S3 type Red/Yellow IP65 1438 3111	320 mm 1400 1232	2 P 3890 2U12 <sup>(1)</sup>		2 P 3898 2120
	3 P	38U1 3120	S4 type Red/Yellow IP65 1444 3111					

(1) Terminal shrouds for FUSERBLOC fitted fuse blown microswitch.

## Accessories

### FUSERBLOC for UR fuses type K/110

#### Terminal shrouds for FUSERBLOC fitted fuse blown microswitch

##### Use


Protection against direct contact with live parts situated in the fuse compartment for FUSERBLOC fitted with UR fuses with fuse blown auxiliary contacts.

Rating (A)	Fuses <sup>(3)</sup>	No. of poles	Accessories <sup>(1)</sup>	
			Reference	Option <sup>(2)</sup> Reference
250... 400	1* / 1	2 P	3999 2839	3990 2839
250... 400	1* / 1	3 P	3999 3839	3990 3839
500 ... 800	2 / 3	2 P	3899 2U63	
500 ... 800	2 / 3	3 P	3899 2U63	3890 3U63
1250	3	2 P	3899 2U12	3890 2U12
1250	3	3 P	3899 3U12	3890 3U12
500 ... 800	2 / 3	2 P		3890 2U63

(1) If ordered later.

(2) If ordered at the same time as the standard device.

(3) For the fuses: see "UR fuses 10 to 2000 A" page

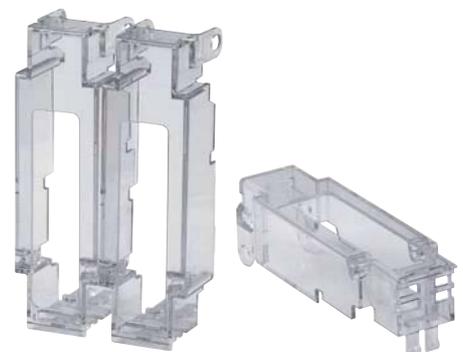

access\_221\_a

Other accessories: see the FUSERBLOC pages