

References

Rating (A)	No. of poles	Switch body	Direct handle	External handle	Shaft for external handle	Bridging bars	Auxiliary contact	Terminal shrouds	Terminal screens
125 A	12 + 4 P	4100 9813	S3 type Black IP65 I - O - II 1433 3113	S3 type Black IP65 I - O - II 1433 3113	200 mm 1401 1520	4 P 4109 4019	1 st contact NO/NC included 2 nd contact NO/NC 4109 0021 ⁽¹⁾	4 P 2694 4014 ⁽²⁾⁽³⁾	4 P 1509 4012 ⁽⁴⁾
160 A	12 + 4 P	4100 9816				4 P 4109 4025			
250 A	12 + 4 P	4100 9825				4 P 4109 4039			
400 A	12 + 4 P	4100 9840				4 P 4109 4063			
630 A	12 + 4 P	4100 9863				Black 2799 7062			
800 A	12 + 4 P	4100 9880	4 P 4109 4160						
1000 A	12 + 4 P	4100 9881							
1250 A	12 + 4 P	4100 9882							
1600 A	12 + 4 P	4100 9886							

(1) 2 pieces: one for position I and one for position II.

(2) To fully shroud front, rear, top and bottom 8 references required.

(3) To shroud front switch top and bottom 4 references required.

(4) For complete front protection, order the reference twice.

Accessories

Key handle interlocking system

Locking in position 0 with RONIS EL11AP (lock not supplied)

Rating (A)	Operation	Figure	Reference
125 ... 630	direct	1	4109 1006 ⁽¹⁾
125 ... 630	external	3	1499 7701
800 ... 1600	direct and external	2	Please consult us

(1) Specific handle included.

Locking in positions I, O, II with RONIS EL11AP (lock not supplied)

Rating (A)	Operation	Figure	Reference
125 ... 630	direct	1	4109 1002 ⁽¹⁾
800 ... 1600	direct	2	Please consult us

(1) Specific handle included.

Locking with CASTELL K type lock (lock not supplied)

Rating (A)	Operation	Figure	Reference
125 ... 630	external	3	1499 7702
800 ... 1600	external		Please consult us

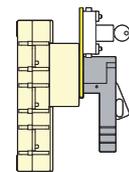


Fig. 1



Fig. 2

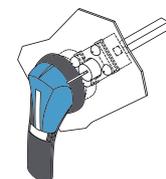


Fig. 3

access_001_a_1_x_cat

access_132_a_1_x_cat

access_156_a_1_x_cat