

## SIRCOVER range

coff\_299\_a\_1\_cat




## References

Rating (A)	No. of poles	Top/Bottom connection I - O - II Reference
125	3 P	4215 3012
125	4 P	4215 4012
160	3 P	4215 3016
160	4 P	4215 4016
250	3 P	4215 3025
250	4 P	4215 4025
400	3 P	4215 3040
400	4 P	4215 4040
630	3 P	4215 3063
630	4 P	4215 4063

## General characteristics

- Adapted to environments subject to chemical, dust, contamination and atmospheric corrosion risks.
- Operation handle: S type black handle, padlockable in position 0.
- Protection degree: IP55 / IK 10.
- Colour: RAL 7030 (range < 400 A), RAL 9002 (range ≥ 400 A).
- Closing plate: N/A.
- Material: glass fibre reinforced polyester.
- Coating: N/A.
- Wall mounting: 4 mounting brackets supplied (not mounted).
- Locking system: square key (ratings < 400 A), 3 mm double bar key (ratings ≥ 400 A), key supplied.
- Miscellaneous: good resistance to creepage currents, high resistance to chemicals, self-extinguishable at 960°C, 2 bolted earth connection points.

## Dimensions

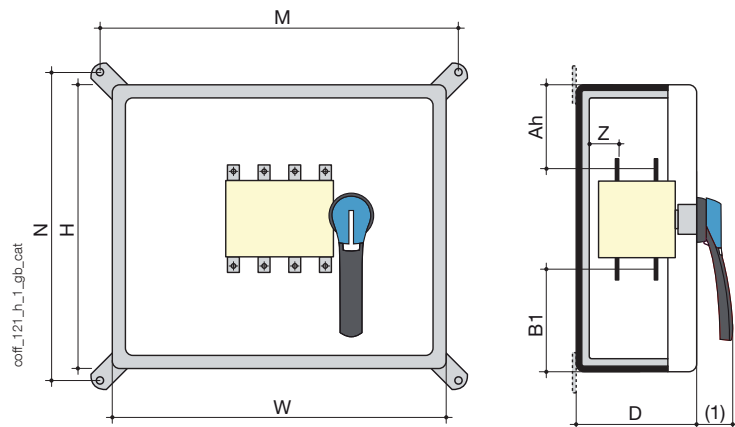

(1) 125 ... 630 A: 45 mm

Rating (A)	No. of poles	H x W x D (mm)	Max. connection cross-section (mm <sup>2</sup> )	M (mm)	N (mm)	Z (mm)	Connection Top/Bottom		
							Ah (mm)	B1 (mm)	Weight (kg)
125	3 P	540 x 270 x 233	50	272	542	28	210	210	9
125	4 P	540 x 360 x 233	50	362	542	28	210	210	10
160	3 P	540 x 270 x 233	95	272	542	28	210	210	9
160	4 P	540 x 360 x 233	95	362	542	28	210	210	10
250	3 P	540 x 360 x 233	150	362	542	29	205	205	11
250	4 P	540 x 360 x 233	150	362	542	29	205	205	12
400	3 P	800 x 600 x 300	240	620	796	29	330	330	30
400	4 P	800 x 600 x 300	240	620	796	29	330	330	31
630	3 P	800 x 600 x 300	2 x 300	620	796	45	297	297	38
630	4 P	800 x 600 x 300	2 x 300	620	796	45	297	297	40