

Mounting rails and profiles

Mounting accessories

Asymmetrical DIN rail

W x H x e (mm)	Perforations (mm)	Perforation centres (mm)	Material	Profiles length (m)	To be ordered in multiples of	Reference
35 x 7.5 x 1	Without		Steel z-b ⁽¹⁾	2	30 m	5000 0302
35 x 7.5 x 1	6.3 x 18	25	Steel z-b ⁽¹⁾	2	30 m	5000 0042
35 x 7.5 x 1	Without		Stainless steel	2	10 m	5000 1302

(1) White zinc-coated.



elcha_040_a_1_cat

Asymmetrical DIN rail

W x H x e (mm)	Perforations (mm)	Perforation centres (mm)	Material	Profiles length (m)	To be ordered in multiples of	Reference
35 x 15 x 1.5	Without		Steel z-b ⁽¹⁾	2	30 m	5000 0301
35 x 15 x 1.5	Without		Steel z-b ⁽¹⁾	3	30 m	5000 0331
35 x 15 x 2.3	Without		Steel z-b ⁽¹⁾	2	20 m	5000 0017
35 x 15 x 2.3	Without		Steel z-b ⁽¹⁾	3	30 m	5000 0027
35 x 15 x 1.5	6.3 x 18	25	Steel z-b ⁽¹⁾	2	30 m	5000 0043
35 x 15 x 1.5	6.3 x 18	25	Steel z-b ⁽¹⁾	3	30 m	5000 0343
35 x 15 x 2.5	Without		Aluminium	2	12 m	SA12 4217
35 x 15 x 2.5	Without		Aluminium	3	18 m	SA13 4217
35 x 15 x 2.5	Without		Aluminium	6	36 m	SA10 4217

(1) White zinc-coated.



elcha_043_a_1_cat

Asymmetrical DIN rail

W x H x e (mm)	Perforations (mm)	Perforation centres (mm)	Material	Profiles length (m)	To be ordered in multiples of	Reference
32 x 15 x 1.5	Without		Steel z-b ⁽¹⁾	2	30 m	5000 0307
32 x 15 x 1.5	Without		Steel z-b ⁽¹⁾	3	30 m	5000 0308
32 x 15 x 1.5	6.3 x 18	25	Steel z-b ⁽¹⁾	2	30 m	5000 0044
32 x 15.5 x 1.5	Without		Aluminium	2	8 m	SA12 4210
32 x 15.5 x 1.5	Without		Aluminium	3	12 m	SA13 4210
32 x 15.5 x 1.5	Without		Aluminium	6	24 m	SA10 4210

(1) White zinc-coated.



elcha_041_a_1_cat


Accessories

Fixomega / Fixocap


Type	Insert M	To be ordered in multiples of	Reference
Fixomega ⁽¹⁾	M4	100	5000 0041
Fixomega ⁽¹⁾	M5	100	5000 0051
Fixocap ⁽²⁾	m3/h	100	5800 0003
White Fixocap ⁽²⁾	M4 / M6	100	5800 0005
Black Fixocap ⁽²⁾	m3/h	100	5800 0004
Grey Fixocap ⁽²⁾	M4 / M6	100	5800 0006

(1) Clip-on nut for symmetrical profiles.

(2) Clip-on nut for asymmetrical profiles.

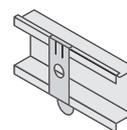

Fixomega

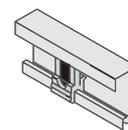

Fixocap

elcha_019_b_1_x_cat

Support for inclined mounting

Type	Number of holes	Ø hole (mm)	Insert M	To be ordered in multiples of	Reference
Support for inclined mounting	2	7	M5	10	5000 0100



elcha_022_a_1_x_cat

Cable support rail

W x H x e (mm)	Perforations (mm)	Perforation centres (mm)	Material	Profiles length (m)	To be ordered in multiples of	Reference
30 x 15 x 1	8.2 x 14.5	16.7	Galvanised steel	3	15 m	5000 4325
50 x 12 x 1	8.2 x 14.5	16.7	Galvanised steel	2	20 m	5000 4326



elcha_033_a_1_cat