

Side Channel Blower Silencers

SLCR, SLCRT Series 1/2" - 4"

Features


- Absorptive media pack
- Designed for minimal pressure drop
- For inlet and discharge inline air service
- Corrosive resistant gray powder coat carbon steel

Technical Specifications


- Max. temperature (continuous): 225°F (107°C)
- Due to the wide range of equipment and environments, please contact factory for typical noise attenuation for your application



Inlet/Outlet		Assembly SCFM Rating	Assembly Part Number	Dimensions (inches)			Approx. Weight (lbs)
Size	Type			A	B	C	
1"	NPSC	42	SLCR100	11.97	0.75	2.50	2
1 1/4"	NPSC	55	SLCR125	12.03	0.75	2.50	2
1 1/2"	NPSC	155	SLCR150	12.03	0.78	2.50	3
2"	NPSC	270	SLCR200	15.73	0.75	3.63	4
2 1/2"	FNPT	385	SLCR250	20.98	1.28	4.65	8
3"	FNPT	575	SLCR300	25.87	1.56	5.18	10
4"	FNPT	575	SLCR400	24.68	1.69	10.00	26
1/2"	MNPT	25	SLCRT050	13.85	1.69	2.50	2
3/4"	MNPT	35	SLCRT075	14.47	2.00	2.50	2
1"	MNPT	42	SLCRT100	14.48	2.00	2.50	2
1 1/4"	MNPT	55	SLCRT125	14.46	2.00	2.50	2
1 1/2"	MNPT	155	SLCRT150	14.47	2.00	2.50	3
2"	MNPT	270	SLCRT200	18.50	2.13	3.63	4
2 1/2"	MNPT	385	SLCRT250	23.68	2.63	4.65	8
3"	MNPT	575	SLCRT300	28.00	2.63	5.18	10
4"	MNPT	575	SLCRT400	29.32	4.00	10.00	26

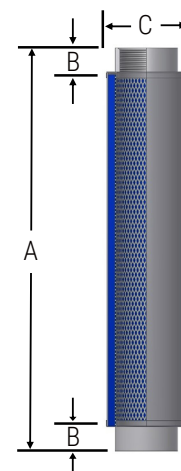

Typical Noise Attenuation

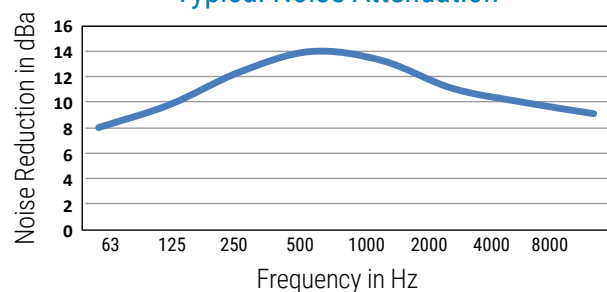

Learn More

For more information about Solberg products and finding the right solutions for your equipment needs, visit us at **SolbergMfg.com**.

All model offerings and design parameters are subject to change without prior notice.
Contact your representative or visit www.solbergmfg.com for the most current information.

Contact Us

solbergmfg.com/locations

