

Part No: 1102-250

Schedule 40 White

Tee

Desc: 2X1-1/4 PVC TRANS TEE SOCXINSXBARB SCH40

MSRP: 8.54

Part Code: 040

Weight(lbs): 0.34

Weight(kg): 0.154

Weight(gm): 154


Size: 2"X2"X1-1/4"

Color: WHITE

Material: PVC

Connection Socket x Socket x Insert

Type Standard

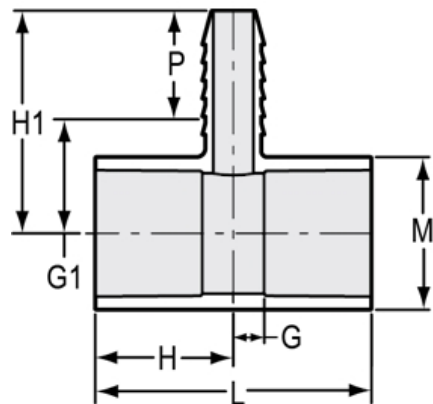

G = 11/16

G1 = 1-1/2

H = 2- 1/16

H1 = 3

L = 4- 1/8

M = 2- 3/4

P = 1- 1/2

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

