

Part No: 1406-012

Inserts

Elbow

Desc: 1-1/4 PVC INSERT 90 ELL INSERTXINSERT

MSRP: 4.9

Part Code: 140

Weight(lbs): 0.119

Weight(kg): 0.054

Weight(gm): 54


Size: 1-1/4"

Color: GRAY

Material: PVC

Connection Insert x Insert

Type Standard

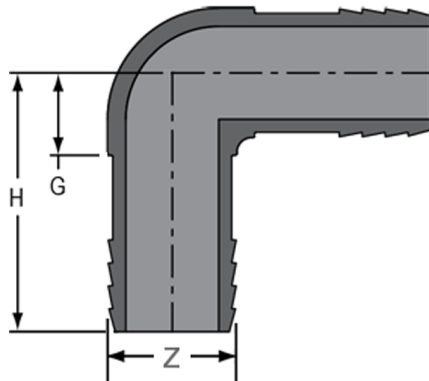

G = 27/32

H = 2-11/32

Z = 1-13/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

