

**Part No:** 1406-020

**Inserts**

**Elbow**

**Desc:** 2 PVC INSERT 90 ELL INSERTXINSERT

**MSRP:** 8.07

**Part Code:** 140

**Weight(lbs):** 0.234

**Weight(kg):** 0.106

**Weight(gm):** 106


**Size:** 2"

**Color:** GRAY

**Material:** PVC

**Connection** Insert x Insert

**Type** Standard

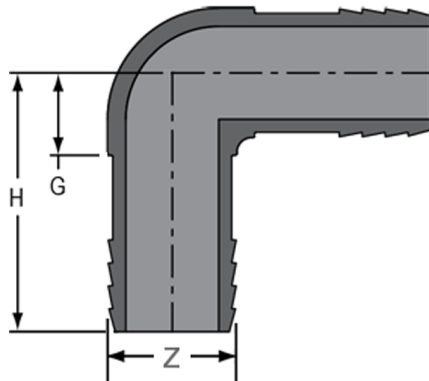

**G** = 1-3/16

**H** = 2-15/16

**Z** = 2-3/32

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/32$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses;  $\pm 1/32$  inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/32$  inch

**L** = Overall length of fittings;  $\pm 1/16$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/16$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/16$  inch.

**W** = Height of cap;  $\pm 1/16$  inch

## Typical Molded Dimension References

