

Part No: 1407-015

Inserts

Elbow

Desc: 1-1/2 PVC INSERT 90 ELL INSERTXFPT

MSRP: 8.58

Part Code: 140

Weight(lbs): 0.236

Weight(kg): 0.107

Weight(gm): 107


Size: 1-1/2"

Color: GRAY

Material: PVC

Connection Insert x Fipt

Type Standard

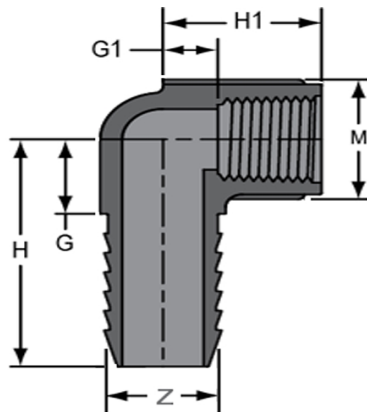

G = 1-1/4

G1 = 27/32

H = 3

H1 = 1-7/8

M = 2-3/8

Z = 1-21/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

