

Part No: 162B-005CLSR

Valves

Y-Check Valve

Desc: 1/2 PVC CLR T/U Y-CHECK VLVE SR/FPT EPDM

MSRP: 167.71

Part Code: 628

Weight(lbs): 0.586

Weight(kg): 0.266

Weight(gm): 266

Size: 1/2"


Color: CLEAR

Material: PVC

Connection SR Fipt (True Union)

Body Color Clear

O-Ring EPDM

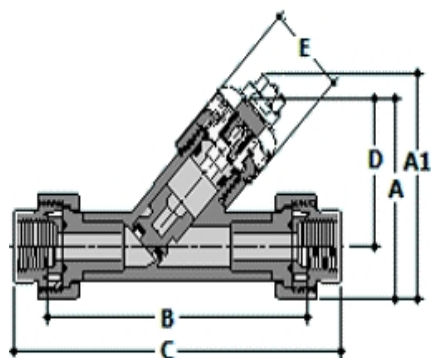

A = 3- 1/2

A1 = 4- 3/8

B = 5- 1/2

C = 7

D = 2-19/32

E = 1- 5/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

