

Part No: 162B-007CLSR

Valves

Y-Check Valve

Desc: 3/4 PVC CLR T/U Y-CHECK VLVE SR/FPT EPDM

MSRP: 181.26

Part Code: 628

Weight(lbs): 1.036

Weight(kg): 0.47

Weight(gm): 470

Size: 3/4"


Color: CLEAR

Material: PVC

Connection SR Fipt (True Union)

Body Color Clear

O-Ring EPDM

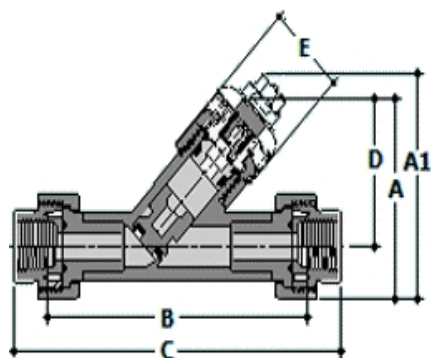

A = 4- 9/32

A1 = 5- 5/16

B = 6-13/32

C = 8

D = 3- 5/32

E = 2

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

