

Part No: 162B-012CLSR

Valves

Y-Check Valve

Desc: 1-1/4 PVC T/U CLR Y-CHECK VLV SRFPT EPDM

MSRP: 316.54

Part Code: 628

Weight(lbs): 2.282

Weight(kg): 1.035

Weight(gm): 1035

Size: 1-1/4"


Color: CLEAR

Material: PVC

Connection SR Fipt (True Union)

Body Color Clear

O-Ring EPDM

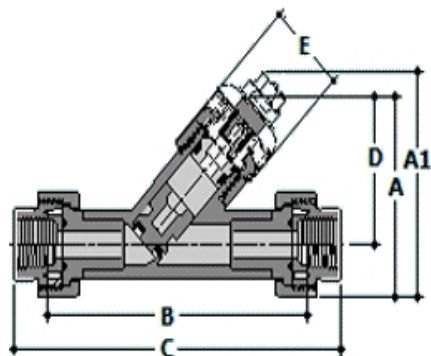

A = 5-13/16

A1 = 7- 1/16

B = 8- 7/32

C = 10- 5/32

D = 4- 9/32

E = 2-13/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

