

**Part No:** 162B-015CL

**Valves**

**Y-Check Valve**

**Desc:** 1-1/2 PVC T/U CLEAR Y-CHECK VLV FPT EPDM

**MSRP:** 327.4

**Part Code:** 628

**Weight(lbs):** 2.873

**Weight(kg):** 1.303

**Weight(gm):** 1303

**Size:** 1-1/2"


**Color:** CLEAR

**Material:** PVC

**Connection** Fipt (True Union)

**Body Color** Clear

**O-Ring** EPDM

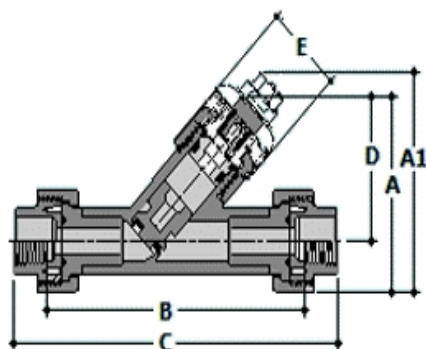

**B** = 9

**C** = 11-1/16

**D** = 4-7/8

**E** = 3-5/32

**A1** = 8-1/8

**A** = 6-5/8

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/32$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses;  $\pm 1/32$  inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/32$  inch

**L** = Overall length of fittings;  $\pm 1/16$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/16$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/16$  inch.

**W** = Height of cap;  $\pm 1/16$  inch

## Typical Molded Dimension References

