

**Part No:** 162B-030CLSR

**Valves**

**Y-Check Valve**

**Desc:** 3 PVC T/U CLEAR Y-CHECK VALVE FPT EPDM

**MSRP:** 882.02

**Part Code:** 628

**Weight(lbs):** 13.237

**Weight(kg):** 6.004

**Weight(gm):** 6004

**Size:** 3"


**Color:** CLEAR

**Material:** PVC

**Connection** SR Fipt (True Union)

**Body Color** Clear

**O-Ring** EPDM

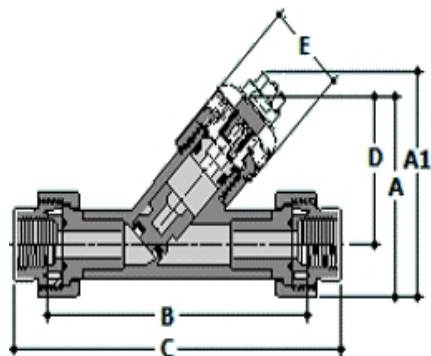

A = 10- 5/8

A1 = 13- 7/16

B = 15-11/32

C = 18- 7/32

D = 7- 9/16

E = 5- 1/4

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/32$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses;  $\pm 1/32$  inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/32$  inch

**L** = Overall length of fittings;  $\pm 1/16$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/16$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/16$  inch.

**W** = Height of cap;  $\pm 1/16$  inch

## Typical Molded Dimension References

