

Part No: 162B-040C

Valves

Y-Check Valve

Desc: 4 CPVC T/U Y-CHECK VALVE FPT EPDM

MSRP: 1999.44

Part Code: 629

Weight(lbs): 23.85

Weight(kg): 10.818

Weight(gm): 10818

Size: 4


Color: GRAY

Material: CPVC

Connection Fipt (True Union)

Body Color Gray

O-Ring EPDM

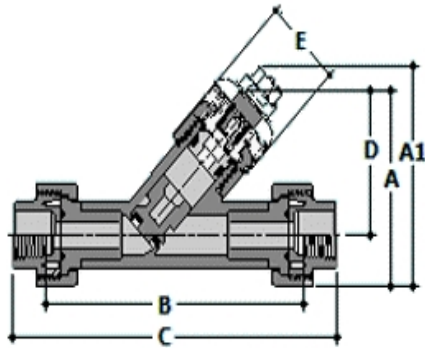

A1 = 16-3/4

A = 13-5/8

B = 19-9/32

C = 22-5/16

D = 9-25/32

E = 6-17/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

